




LED FIL A60 E27 12V-42V AC/DC 4W 400lm (35W) 840 Opal

Article number: 146595

BAI LED Filament GLS A60 E27 Low voltage 12V-24V-28V-32V-42V AC/DC 4W 400lm (35W) 4000K Opal 320° 60x110mm LED-lamp

LED filament lamps can be seen as the modern sustainable version of the old incandescent lamp. The so-called filaments replace the traditional filament, making the lamps many times more energy-efficient and last much longer. This low voltage series is especially suitable for rooms where one is not on the usual high-voltage network. Think of boats, cellars, garages and storage areas.

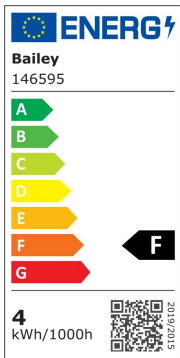

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED FIL A60 E27 12V-42V AC/DC 4W 400lm (35W) 840 Opal
Brand	Bailey
Productseries	Low voltage LED bulb
Producttype	A60 FIL Opal

ETIM specifications

Socket	E27
Luminous flux [lm]	400 - 400
Nominal voltage [V]	12 - 42
Lamp power [W]	4 - 4
Colour temperature [K]	4000 - 4000
Diameter [mm]	60
Length [mm]	110
Dimmable	No
Lamp shape	Pear-shape
Beam angle [°]	320 - 320
Colour	White
Type of glass/cover	Opal
Lamp designation	A-type
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	Yes
Rated luminous flux according to IEC 62612 [lm]	400
Power factor	0.7
Lamp efficacy [lm/W]	100
Nominal current [mA]	200 - 200
Colour of light according to EN 12464-1	Neutral white 3300-5300 K
Housing colour	White
Average nominal lifetime [h]	15000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	15000
Weighted energy consumption in 1000 hours [kWh]	4
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG0
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	No
Dimming phase cut-on (leading edge)	No
Dimming Touch and Dim	No
Dimming Zigbee	No

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	F
With twilight switch	No
Material of light bulb	Glass

Complementary articles



146219
TOPO Little Transformer 12V AC
0-50W / LED 0-20W DIM



145683
TOPO Mini Transformer 12V AC
0-50W / LED 0-30W DIM