

# Protective covers - HC-STA-B24-DC-PL - 1421103

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




Protective covers, type: B24, degree of protection: IP20, color: transparent/white



COMPLIANT

## Key Commercial Data

Packing unit	5 pc
Minimum order quantity	5 pc
GTIN	 4 055626 251837
GTIN	4055626251837
Weight per Piece (excluding packing)	10.500 g
Custom tariff number	85389099
Country of origin	China
Note	Made to Order (non-returnable)

## Technical data

### Dimensions

Height	22.1 mm
Width	46.4 mm
Length	123.2 mm

### Ambient conditions

Degree of protection (IP)	IP20
Ambient temperature (operation)	0 °C ... 20 °C

### General

Size	B24
Housing type	Protective cover
Color	transparent
Locking type	Clip locking
Material, protective cover	PA

# Protective covers - HC-STA-B24-DC-PL - 1421103

## Technical data

### General

Flammability rating according to UL 94	HB
--	----

### Standards and Regulations


Flammability rating according to UL 94	HB
--	----

### Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

## Drawings

Dimensional drawing

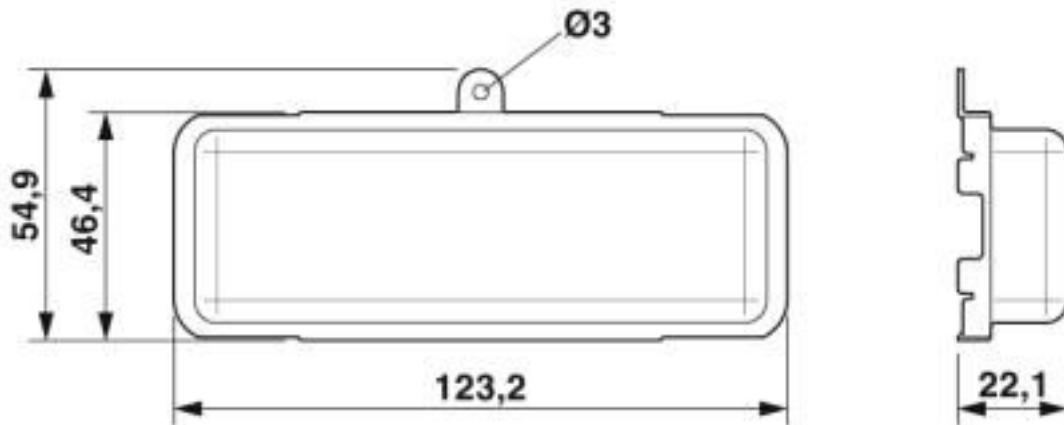

Dimensional drawing

## Classifications

### eCl@ss

eCl@ss 10.0.1	27440208
eCl@ss 5.1	27260700
eCl@ss 6.0	27261200
eCl@ss 7.0	27440208
eCl@ss 8.0	27440208
eCl@ss 9.0	27440208

### ETIM

ETIM 5.0	EC002314
ETIM 6.0	EC002314
ETIM 7.0	EC002314

### UNSPSC

UNSPSC 13.2	39121421
-------------	----------

# Protective covers - HC-STA-B24-DC-PL - 1421103

## Classifications

### UNSPSC

UNSPSC 18.0	39121421
UNSPSC 19.0	39121421
UNSPSC 20.0	39121421
UNSPSC 21.0	39121421

## Approvals

### Approvals

---

Approvals

DNV GL

---

Ex Approvals

---

### Approval details

DNV GL		<a href="https://approvalfinder.dnvgl.com/">https://approvalfinder.dnvgl.com/</a>	TAE000037S
--------	---	---	------------

---