

COMBAT TROUSER

TR222

PRODUCT DESCRIPTION

Our Arc Combat Trousers deliver durable protection with ripstop stretch fabric that moves with you. With a secure waistband, reinforced kneepad pockets, and pre-bent knees, it's built for comfort and flexibility in demanding environments.

Certified to APC 1 with an 8 cal/cm² ELIM rating, the TR222 integrates SafetyICON™ technology, keeping you informed about your protection level. Triple-stitched seams and reinforced hems ensure it stands up to the toughest tasks, wear after wear.

PRODUCT DETAILS

FITS: Male & Female

MALE SIZES: 30-42" Short | 30"-52" Regular | 30-44" Tall (TR222M)

FEMALE SIZES: 8-18 Regular (TR222F)

More sizes & fits are available but are not stocked.
Leadtimes will apply.





COLOUR: Navy



BOX TEST ARC RATING



EN STANDARDS

 EN ISO 11612: 2015	 EN 1149-5: 2018	 EN 61482-2: 2020	 EN 13758-2:2003 +A1:2006
A1, B1 C1, F1	Pt. 5:2018 Pt. 3:2004 Charge Decay	APC 1 ELIM=8cal/cm ²	UPF 40+

COMBAT TROUSER

TR222

FEATURES & BENEFITS

- ✓ Waistband with concealed swivel front fastening
- ✓ Navy slanted hip pockets to minimise visible dirt in high traffic area
- ✓ FR Spiral zip for increase strength
- ✓ Gusset for ease of movement
- ✓ Combat pocket style with phone pocket on left hand side as worn
- ✓ Ruler/Tool pockets behind side seam on right hand side as worn
- ✓ Concealed D-ring to inner pocket
- ✓ Top loading reinforced kneepad pocket with positional bar tacks
- ✓ Pre-bent knees for ease of movement
- ✓ Triple needle stitching
- ✓ Reinforced hems
- ✓ 5 wide belt loops
- ✓ Large back belt loop to prevent belt from rising
- ✓ SafetyCON with ELIM rating

FABRIC SPECIFICATION:

- ✓ Weight: 265gms
- ✓ Weave Type: Ripstop Stretch

PRODUCT CARE:

- ✓ Maximum washing temp 60°C
- ✓ Drying temperature: up to 60°C
- ✓ Ironing: Medium temperature
- ✓ Dry clean permissible
- ✓ Do not use bleach



Concealed swivel front fastening



Combat pocket style



Pre-bent knees for ease of movement



COMBAT TROUSER

WEARER FIT GUIDE - FEMALE

SHORT (Height 157-164cm / 62-65 Inches | Inside Leg 76cm / 30 Inches)

UK SIZE	DE SIZE	WAIST (cm / Inches)		HIP (cm / Inches)	
8s	17	68-73cm	27"-29"	88-93cm	34"-37"
10s	18	73-78cm	29"-31"	93-98cm	37"-39"
12s	19	78-83cm	31"-33"	98-103cm	39"-41"
14s	20	83-88cm	33"-35"	103-108cm	41"-43"
16s	21	88-93cm	35"-37"	108-113cm	43"-45"
18s	22	93-98cm	37"-39"	113-118cm	45"-47"
20s	23	98-103cm	39"-41"	118-123cm	47"-49"
22s	24	103-108cm	41"-43"	123-128cm	49"-51"
24s	25	108-113cm	43"-45"	128-133cm	51"-53"

REGULAR (Height 164-172cm / 65-68 Inches | Inside Leg 81cm / 32 Inches)

UK SIZE	DE SIZE	WAIST (cm / Inches)		HIP (cm / Inches)	
8R	34	68-73cm	27"-29"	88-93cm	34"-37"
10R	36	73-78cm	29"-31"	93-98cm	37"-39"
12R	38	78-83cm	31"-33"	98-103cm	39"-41"
14R	40	83-88cm	33"-35"	103-108cm	41"-43"
16R	42	88-93cm	35"-37"	108-113cm	43"-45"
18R	44	93-98cm	37"-39"	113-118cm	45"-47"
20R	46	98-103cm	39"-41"	118-123cm	47"-49"
22R	48	103-108cm	41"-43"	123-128cm	49"-51"
24R	50	108-113cm	43"-45"	128-133cm	51"-53"

TALL (Height 172-180cm / 68-71 Inches | Inside Leg 86cm / 34 Inches)

UK SIZE	DE SIZE	WAIST (cm / Inches)		HIP (cm / Inches)	
8T	68	68-73cm	27"-29"	88-93cm	34"-37"
10T	72	73-78cm	29"-31"	93-98cm	37"-39"
12T	76	78-83cm	31"-33"	98-103cm	39"-41"
14T	80	83-88cm	33"-35"	103-108cm	41"-43"
16T	84	88-93cm	35"-37"	108-113cm	43"-45"
18T	88	93-98cm	37"-39"	113-118cm	45"-47"
20T	92	98-103cm	39"-41"	118-123cm	47"-49"
22T	96	103-108cm	41"-43"	123-128cm	49"-51"
24T	100	108-113cm	43"-45"	128-133cm	51"-53"

MEASURING INSTRUCTIONS

Measurements must be taken wearing clothing usually worn underneath waterproof outerwear. The tape measure should be fairly loose and not pulled too tight.


- ✓ **CHEST/BUST** - measure under the arms at the fullest part around the chest horizontally with arms by your side
- ✓ **WAIST** - measure around the natural waistline at the fullest part
- ✓ **SEAT/HIP** - with the feet together measure around fullest part of the hips
- ✓ **HEIGHT** - with bare feet together measure from the top of the head to the floor
- ✓ **INSIDE LEG** - in bare feet take the measurement from the top of the inside leg and measure down the inside leg to the floor

Once measurements are taken compare them to the fit guide measurement tables to find your garment size.

When fitting the trouser if the waist and seat measurements fall into different size categories then choose the larger size to ensure the trouser is not too close fitting.

If the height and inside leg measurements fall into different length categories then choose the jacket length based on the height measurement and the trouser length based on the inside leg measurement.

Please note when using the measurement tables that all manufacturing tolerances and standard garment over-measures have been taken into account. This ensures any slight variances in manufacture or fabric shrinkage after washing will not affect the fit of the garments.

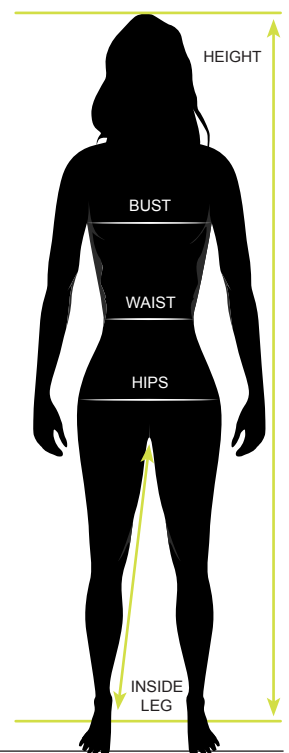

COMBAT TROUSER

WEARER FIT GUIDE - MALE

SHORT (Height 164-172cm / 65-68 Inches | Inside Leg 76cm / 30 Inches)


UK SIZE	DE SIZE	WAIST (cm / Inches)		UK SIZE	DE SIZE	WAIST (cm / Inches)	
28s	21	70-75cm	28"-30"	42s	29	105-110cm	42"-44"
30s	22	75-80cm	30"-32"	44s	30	110-115cm	44"-46"
32s	23	80-85cm	31"-33"	46s	31	115-120cm	46"-47"
34s	24	85-90cm	33"-35"	48s	32	120-125cm	47"-49"
35s	25	90-95cm	35"-37"	50s	33	125-130cm	49"-51"
36s	26	95-98cm	37"-39"	52s	34	130-135cm	51"-53"
38s	27	98-100cm	39"-40"	54s	35	135-140cm	53"-55"
40s	28	100-105cm	40"-42"	56s	36	140-145cm	55"-57"

REGULAR (Height 172-180cm / 68-71 Inches | Inside Leg 81cm / 32 Inches)

UK SIZE	DE SIZE	WAIST (cm / Inches)		UK SIZE	DE SIZE	WAIST (cm / Inches)	
28R	42	70-75cm	28"-30"	42R	58	105-110cm	42"-44"
30R	44	75-80cm	30"-32"	44R	60	110-115cm	44"-46"
32R	46	80-85cm	31"-33"	46R	62	115-120cm	46"-47"
34R	48	85-90cm	33"-35"	48R	64	120-125cm	47"-49"
35R	50	90-95cm	35"-37"	50R	66	125-130cm	49"-51"
36R	52	95-98cm	37"-39"	52R	68	130-135cm	51"-53"
38R	54	98-100cm	39"-40"	54R	70	135-140cm	53"-55"
40R	56	100-105cm	40"-42"	56R	72	140-145cm	55"-57"

TALL (Height 180-188cm / 71-74 Inches | Inside Leg 86cm / 34 Inches)

UK SIZE	DE SIZE	WAIST (cm / Inches)		UK SIZE	DE SIZE	WAIST (cm / Inches)	
28T	86	70-75cm	28"-30"	42T	118	105-110cm	42"-44"
30T	90	75-80cm	30"-32"	44T	122	110-115cm	44"-46"
32T	94	80-85cm	31"-33"	46T	126	115-120cm	46"-47"
34T	98	85-90cm	33"-35"	48T	130	120-125cm	47"-49"
35T	102	90-95cm	35"-37"	50T	134	125-130cm	49"-51"
36T	106	95-98cm	37"-39"	52T	138	130-135cm	51"-53"
38T	110	98-100cm	39"-40"	54T	142	135-140cm	53"-55"
40T	114	100-105cm	40"-42"	56T	146	140-145cm	55"-57"

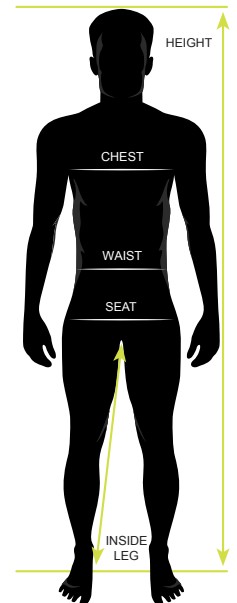

MEASURING GUIDE

Measurements must be taken wearing clothing usually worn underneath waterproof outerwear.

The tape measure should be fairly loose and not pulled too tight.

- ✓ **WAIST** - measure around the natural waistline at the fullest part
- ✓ **SEAT** - with the feet together measure around fullest part of the hips
- ✓ **HEIGHT** - with bare feet together measure from the top of the head to the floor
- ✓ **INSIDE LEG** - in bare feet take the measurement from the top of the inside leg and measure down the inside leg to the floor

Once measurements are taken compare them to the fit guide measurement tables to find your garment size.

When fitting the trouser if the waist and seat measurements fall into different size categories then choose the larger size to ensure the trouser is not too close fitting.

If the height and inside leg measurements fall into different length categories then choose the jacket length based on the height measurement and the trouser length based on the inside leg measurement.

Please note when using the measurement tables that all manufacturing tolerances and standard garment over-measures have been taken into account. This ensures any slight variances in manufacture or fabric shrinkage after washing will not affect the fit of the garments.