




ENGLISH

Datasheet

Stock No: 248-9247

RS Pro Steel Rule Imperial or Metric 300 (12in)mm

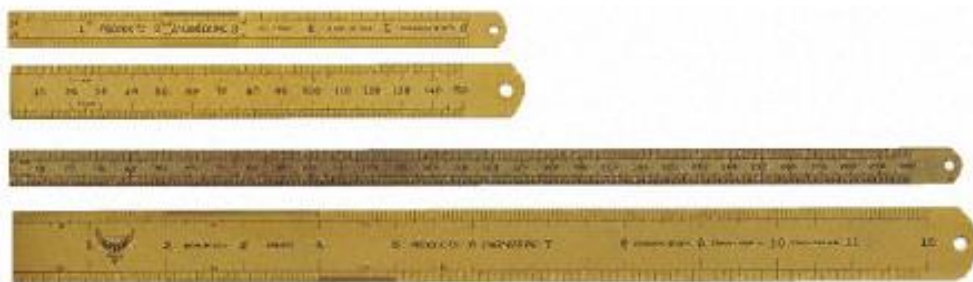

Product Details

Titanium Nitride-coated

Titanium Nitride coated steel rules with paint filled engraved graduations. These rules are extremely hard wearing, low glare and high contrast measurement. All rules have "D" ends and are available as rigid or flexible.

Specifications:

Length	300 (12in)mm
Imperial or Metric	Both
Material	Steel
Width	12.5mm
Finish	Anti-Glare
Calibrated	Yes
Flexible	Yes



ENGLISH

Type	Width	Thickness	Graduation (all rules)
Flexible			Imperial Face
6in./150mm	12.5	0.4	1//10, 1//16, 1//20, 1//32, 1//50
12in./300mm	12.5	0.4	1//64, 1//100, 1//4, 1//2 & 1in.
Rigid			Metric Face
6in./150mm	19.0	1.0	
12in./300mm	25.0	1.0	0.5mm, 1mm, 5mm, 10mm

Rules

Name	Symbol	Conversion factor
in	in	25,4 mm
ft	ft	0,3045 m
yard	yd	0,9144 m
mile	mile	1609,344 m
nau.mil	nau.mil	1852 m