




 





 







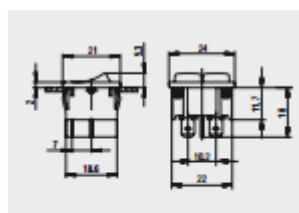



# MARQUARDT

## SERIES 1800 - SINGLE AND DOUBLE-POLE ROCKER SWITCHES

TO 12 (4) A 250 V AC

Combination	ON/OFF switch (SPST) / Lamp	1806.1402	Normally open contact (SPNO) / Switch (SPDT)	1806.2054	Lamp / Changeover switch (SPDT momentary)	1806.1909	ON/OFF switch (SPST)	1806.1102	1806.6108	Switch with OFF position in the center (SPDT - Center OFF)	1806.1602
											
Voltage lamp in V		230		230		230					
Actuator color / printing											
Housing color											
12 (4) A 250 V AC 1E4											
10 (4) A 250 V AC 1E4		•									
8 (8) A 250 V AC 5E4		•									
6 (4) A 250 V AC 5E4		•									
6 (2) A 250 V AC 1E4											•
4 (3) A 250 V AC 6E3											
4 (2) A 250 V AC 1E4											
30 mA 12 V 5E4				•							
30 mA 12 V DC 5E4											
15 A 250 V AC 1 1/2 HP											
15 A 125 V AC 3/4 HP											
10 A 250 V AC 1/2 HP											
10 A 125 V AC 1/3 HP											
6 A 250 V AC 1/2 HP		•				•		•	•		
6 A 125 V AC 1/4 HP		•				•		•	•		
6 A 125 - 250 V AC 1/8 HP											
6 A 125 V AC 1/10 HP											
4 A 250 V AC 1/10 HP											
Connection type											
Connection description		4.8		4.8		4.8		4.8			4.8
Inrush current in A (capacitive)											
Contact distance in mm		≥3		≥3		≥3		≥3	≥3		<3
Contact material		Ag		Ag		Ag		Ag	Ag		Ag
EN 60335 cap. 30 conform *G*											
Miscellaneous									without separating gate		life endurance 50 000 cycles
Stock version		•						•			



 Quick-connect terminal 4.8  
1806.2054 and 1806.1102