

3M Science.
Applied to Life.™



Power Inside.

3M™ Bumpon™ Protective Bumpers
Powerful friends with high
adhesion strength



Small protective bumpers – large effect

3M™ Bumpon™ protective bumpers

Protective bumpers are useful accessories in the industry, trade, electronics and household sectors. They quickly provide anti-skid surfaces, and are used as spacers or stops. They are also excellently suited for absorbing vibrations and noise, and allow for good air circulation.

3M™ Bumpon protective bumpers are made of permanently protective high-quality polyurethane elastomer and coated with synthetic rubber/natural rubber or acrylate adhesive. Thus they adhere to a variety of different surfaces.

Protective bumpers feature high abrasion resistance and adhesive strength, and do not leave any traces on surfaces.

Self-adhesive bumpers are an alternative for traditional screwed or plug-in protective bumpers, thus saving time and costs. Simply remove the bumper from the protective liner, press it down and it's ready – quick and easy application on dry surfaces free from dirt and grease.

3M™ Bumpon™ protective bumpers can be applied easily and quickly.



Remove bumper from the protective liner



Apply bumper



Press it down, ready!

Where can protective bumpers be used?

As vibration-damping, sealing spacers



- Metal sheets, facade elements, device housings, flaps, roller shutters

As anti-skid, vibration-damping device feet



- Household appliances, telephones, laptops, decorative objects made of glass or ceramics

As noise-absorbing, permanently protective stops



- Doors, drawers, windows, walls, furniture, internal lining

As spacers for air circulation



 
- Circuit boards, ventilation of paintings and drawings



High adhesion strength – flexible use.

The right bumper for each application

Colored series



We offer various colors matching your appliances, surfaces and applications, e.g. as feet for household appliances or as spacers on wood.

Standard colors: black, white, grey, brown

Standard shapes: round, square, rectangular, hexagonal

3M™ Bumpon™ protective bumpers Set



A range of 3M™ Bumpons™ protective bumpers in a handy case, ready for a variety of applications.

- Over 700 of the top ten most popular 3M™ Bumpons™ protective bumpers
- Neatly organised into the various colors and shapes
- The selection table is available in 14 languages
- Dust-proof packaging, ready for use on any jobsite

Transparent series



The transparent series allows for the application of invisible protective bumpers on glass, acrylic glass or colored surfaces (wood, plastic, metal).

Standard shapes: round, square, rectangular

3M™ Bumpon™ Mini Pack




A selected range of protective bumpers of the most popular shapes, colors and sizes is also available in practical small amounts – with the same advanced features!

3M™ Bumpon™ Rollstock protective bumpers

For individual die-cut parts 3M™ Bumpon™ Rollstock enables to produce feet, stoppers and spacers in the desired shape and color.

For additional details
about rollstocks please visit
our selection guide:

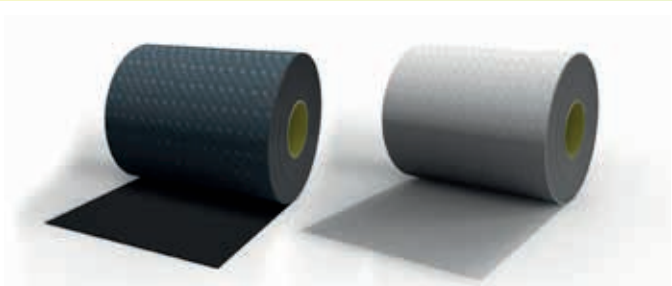

Find the right protective bumpers to meet your requirements.

The right adhesive

Acrylic

Acrylate adhesive - very good shear strength properties, especially for high-energy surfaces such as metal or glass, as well plastics such as polyester, ABS or polycarbonate.

- Excellent temperature resistance
- Excellent solvent resistance
- Excellent aging resistance

Synthetic Rubber

Synthetic rubber - very good tack and very good immediate adhesion, works best for low-energy, coated or structured surfaces such as

- polyethylene
- polypropylene
- polystyrene

Natural Rubber


Natural rubber - high tack, good immediate adhesion. Versatile adhesive with good adhesion properties on almost all surfaces.

The right shape

The right shape alignment



Square shape

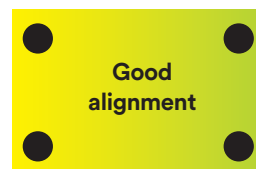

Round shape

Contact area



Flat shape

- High resilience
- Good wear resistance



Hemisphere shape

- High noise-absorption
- Increased absorption energy

Contact area



Flat profile

- High resilience
- Low sensitivity against shearing



Tapered profile

- High heat dissipation











Note:

Not suitable for high shearing load




















3M™ Bumpon™ protective bumpers Mini Packs (1 box = 18 mini packs)



Shape	Type No.	Width Ø in mm	Height in mm	Color	Adhesive	Number of Bumpers/blister	Number of Bumpers/box	MOQ (box)
	SJ5009	22.3	10.1	black	Natural rubber R - 30	6	108	1
	SJ5012	12.7	3.5	black	Natural rubber R - 30	56	1,008	1
	SJ5302	7.9	2.2	transparent	Acrylic A - 20	80	1,440	1
	SJ5308	12.7	3.1	transparent	Acrylic A - 20	40	720	1
	SJ5309	22.3	10.1	transparent	Acrylic A - 20	6	108	1
	SJ5312	12.7	3.5	transparent	Acrylic A - 20	56	1,008	1
	SJ5323	20.5	7.6	transparent	Acrylic A - 20	12	216	1
	SJ5344	19.1	4.1	transparent	Acrylic A - 20	16	288	1
	SJ6553	11.0	3.05	transparent	Synthetic rubber R - 25	132	2,376	1
	SJ5300	3M Bumpon mix		transparent	Acrylic A - 20	20 x SJ5302 14 x SJ5312 8 x SJ5344	360 x SJ5302 252 x SJ5312 144 x SJ5344	1

3M™ Bumpon™ Self-adhesive protective bumpers, transparent

















Shape	Type No.	Width Ø in mm	Height in mm	Color	Adhesive	Number of Bumpers/box	MOQ
	SJ5302	7.9	2.2	transparent	Acrylic A - 20	3,000	3,000
	SJ5303	11.1	5.0	transparent	Acrylic A - 20	3,000	3,000
	SJ5306	9.5	3.8	transparent	Acrylic A - 20	3,000	3,000
	SJ5307	10.4	2.5	transparent	Acrylic A - 20	3,000	3,000
	SJ5308	12.7	3.1	transparent	Acrylic A - 20	3,000	3,000
	SJ5309	22.3	10.1	transparent	Acrylic A - 20	1,000	1,000
	SJ5312	12.7	3.5	transparent	Acrylic A - 20	3,000	3,000
	SJ5317	19.0	9.6	transparent	Acrylic A - 20	1,000	1,000
	SJ5318	12.7	5.8	transparent	Acrylic A - 20	3,000	3,000
	SJ5323	20.5	7.6	transparent	Acrylic A - 20	1,000	1,000
	SJ5327	16.0	7.9	transparent	Acrylic A - 20	1,000	1,000
	SJ5344	19.1	4.1	transparent	Acrylic A - 20	2,600	2,600
	SJ5378	10.2	3.3	transparent	Acrylic A - 20	1,500	1,500
	SJ5382	6.4	1.9	transparent	Acrylic A - 20	3,000	3,000
Soft and clear version							
	SJ6506	9.5	3.8	transparent	Synthetic rubber R - 25	5,000	5,000
	SJ6512	12.7	3.5	transparent	Synthetic rubber R - 25	5,000	5,000
	SJ6553	11.0	3.05	transparent	Synthetic rubber R - 25	5,000	10,000


PU = Packing Unit, MOQ = Minimum Order Quantity per u/m

3M™ Bumpon™ Self-adhesive protective bumpers, colored



Shape	Type No.	Width Ø in mm	Height in mm	Color	Adhesive	Number of Bumpers/box	MOQ
	SJ5003	11.1	5.0	grey	Natural rubber R - 30	3,000	3,000
	SJ5003	11.1	5.0	black	Natural rubber R - 30	3,000	3,000
	SJ5003	11.1	5.0	white	Natural rubber R - 30	3,000	3,000
	SJ5007	10.4	2.5	black	Natural rubber R - 30	3,000	3,000
	SJ5008	12.7	3.1	grey	Natural rubber R - 30	3,000	3,000
	SJ5008	12.7	3.1	black	Natural rubber R - 30	3,000	3,000
	SJ5008	12.7	3.1	white	Natural rubber R - 30	3,000	3,000
	SJ5009	22.3	10.1	grey	Natural rubber R - 30	1,000	1,000
	SJ5009	22.3	10.1	black	Natural rubber R - 30	1,000	1,000
	SJ5009	22.3	10.1	white	Natural rubber R - 30	1,000	1,000
	SJ5012	12.7	3.5	grey	Natural rubber R - 30	3,000	3,000
	SJ5012	12.7	3.5	black	Natural rubber R - 30	3,000	3,000
	SJ5012	12.7	3.5	white	Natural rubber R - 30	3,000	3,000
	SJ5017	19.0	9.6	grey	Natural rubber R - 30	1,000	1,000
	SJ5017	19.0	9.6	black	Natural rubber R - 30	1,000	1,000
	SJ5017	19.0	9.6	white	Natural rubber R - 30	1,000	1,000
	SJ5018	12.7	5.8	grey	Natural rubber R - 30	3,000	3,000
	SJ5018	12.7	5.8	black	Natural rubber R - 30	3,000	3,000
	SJ5018	12.7	5.8	white	Natural rubber R - 30	3,000	3,000
	SJ5023	20.5	7.6	grey	Natural rubber R - 30	1,000	1,000
	SJ5023	20.5	7.6	black	Natural rubber R - 30	1,000	1,000
	SJ5023	20.5	7.6	white	Natural rubber R - 30	1,000	1,000
	SJ5027	16.0	7.9	grey	Natural rubber R - 30	1,000	1,000
	SJ5027	16.0	7.9	black	Natural rubber R - 30	1,000	1,000
	SJ5027	16.0	7.9	white	Natural rubber R - 30	1,000	1,000
	SJ5076	8.0	2.8	red-orange	Natural rubber R - 30	30,000	30,000
	SJ5076	8.0	2.8	black	Natural rubber R - 30	3,000	3,000
	SJ5510*	12.7	3.8	black	Natural rubber R - 30	5	5
	SJ5514	20.6	13.1	grey	Natural rubber R - 30	1,000	1,000
	SJ5514	20.6	13.1	black	Natural rubber R - 30	1,000	1,000
	SJ5514	20.6	13.1	white	Natural rubber R - 30	1,000	1,000
	SJ5532	47.7	16.7	grey	Natural rubber R - 30	100	100
	SJ5705	32.4	6.4	black	Natural rubber R - 30	1,000	1,000
	SJ5744	19.1	4.1	black	Natural rubber R - 30	2,600	2,600
	SJ5780	20.0	5.5	black	Natural rubber R - 30	2,600	2,600
	SJ6115	15.9	4.75	black	Synthetic rubber R - 25	3,000	3,000
	SJ6125	15.9	6.35	black	Synthetic rubber R - 25	3,000	3,000
	SJ6344	19.1	4.1	black	Synthetic rubber R - 25	2,600	2,600
	SJ5201	11.0	3.2	light brown	Synthetic rubber R - 25	3,000	3,000
	SJ5202	11.0	1.6	light brown	Synthetic rubber R - 25	3,000	3,000

3M™ Bumpon™ Self-adhesive protective bumpers, rollstock, roll width 114 mm

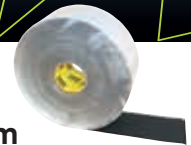

Type No.	Thickness in mm	Roll length in m	Shore hardness	Color	Adhesive	u/m in rolls	MOQ
SJ5808	3.2	33.0	A 60-70	black	Natural rubber R - 30	1	1
SJ5816	1.6	33.0	A 60-70	black	Natural rubber R - 30	1	1
SJ5816	1.6	33.0	A 75	brown	Natural rubber R - 30	1	1
SJ5816	1.6	33.0	A 60-70	white	Natural rubber R - 30	1	1
SJ5832	0.8	66.0	A 60-70	black	Natural rubber R - 30	1	1
SJ5832	0.8	66.0	A 60-70	white	Natural rubber R - 30	1	1
SJ5616	1.6	33.0	A 60-70	transparent	Acrylic A - 20	1	1
SJ5632	0.8	66.0	A 60-70	transparent	Acrylic A - 20	1	1
SJ5904	6.4	16.5	A 32-40	black	Acrylic A - 20	1	1
SJ5908	3.2	33.0	A 32-40	black	Acrylic A - 20	1	1
SJ5916	1.6	33.0	A 32-40	black	Acrylic A - 20	1	1
SJ6005	5.0	22.0	A 75	black	Natural rubber R - 30	1	1
SJ6008	3.2	33.0	A 60-70	black	Acrylic A - 20	1	1
SJ6016	1.6	33.0	A 60-70	black	Acrylic A - 20	1	1
SJ6032	0.8	66.0	A 60-70	black	Acrylic A - 20	1	1
SJ6208	3.2	33.0	A 60-70	black	Synthetic rubber R - 25	1	1
SJ6216	1.6	33.0	A 60-70	black	Synthetic rubber R - 25	1	1

3M™ Bumpon™ Self-adhesive protective bumpers, rollstock, roll width 228 mm



Type No.	Thickness in mm	Roll length in m	Shore hardness	Color	Adhesive	u/m in rolls	MOQ
SJ5916	1.6	33.0	A 32-40	black	Acrylic A - 20	1	1

3M™ Bumpon™ Set

Mix of over 700 bumpers of the 10 most common types in a handy case.

Type No.	Content Bumpon types	Color	MOQ
SET 017	  SJ5012   SJ5202   SJ5302   SJ5303   SJ5309   SJ5312   SJ5318   SJ5323   SJ5344   SJ6553	black light brown transparent transparent transparent transparent transparent transparent transparent transparent	1





**Contact your 3M™ sales representative or visit
3M™ Bumpon™ Protective Products | 3M United Kingdom.**



Regulatory: For regulatory information about this product, contact your 3M representative.

Technical Information: The technical information, guidance, and other statements contained in this document or otherwise provided by 3M are based upon records, tests, or experience that 3M believes to be reliable, but the accuracy, completeness, and representative nature of such information is not guaranteed. Such information is intended for people with knowledge and technical skills sufficient to assess and apply their own informed judgment to the information. No license under any 3M or third party intellectual property rights is granted or implied with this information.

Product Use: Many factors beyond 3M's control and uniquely within user's knowledge and control can affect the use and performance of a 3M product in a particular application. As a result, customer is solely responsible for evaluating the product and determining whether it is appropriate and suitable for customer's application, including conducting a workplace hazard assessment and reviewing all applicable regulations and standards (e.g., OSHA, ANSI, etc.). Failure to properly evaluate, select, and use a 3M product in accordance with all applicable instructions and with appropriate safety equipment, or to meet all applicable safety regulations, may result in injury, sickness, death, and/or harm to property.

Warranty, Limited Remedy, and Disclaimer: Unless a different warranty is specifically stated on the applicable 3M product packaging or product literature (in which case such warranty governs), 3M warrants that each 3M product meets the applicable 3M product specification at the time 3M ships the product. **3M MAKES NO OTHER WARRANTIES OR CONDITIONS, EXPRESS OR IMPLIED, INCLUDING, BUT NOT LIMITED TO, ANY IMPLIED WARRANTY OR CONDITION OF MERCHANTABILITY, FITNESS FOR A PARTICULAR PURPOSE, OR ANY IMPLIED WARRANTY OR CONDITION ARISING OUT OF A COURSE OF DEALING, CUSTOM, OR USAGE OF TRADE.** If a 3M product does not conform to this warranty, then the sole and exclusive remedy is, at 3M's option, replacement or repair of the 3M product or refund of the purchase price.

Limitation of Liability: Except for the limited remedy stated above, and except to the extent prohibited by applicable law, 3M will not be liable for any loss or damage arising from or related to the 3M product, whether direct, indirect, special, incidental, or consequential (including, but not limited to, lost profits or business opportunity), regardless of the legal or equitable theory asserted, including, but not limited to, warranty, contract, negligence, or strict liability.

Disclaimer: For industrial use only. Not intended, labeled or packaged for consumer sale or use.



Electronics Materials Solutions Division

3M United Kingdom plc
3M Centre
Cain Road, Bracknell
Berkshire RG12 8HT
United Kingdom
www.3M.co.uk/

© 3M 2024. All rights reserved.
Please recycle.

3M and Bumpon are trademarks of 3M Company.
Used under license by 3M subsidiaries and affiliates.