


Part Number: 1900X35X

Type	Size	Rating	Description
LED	M6	24Vdc	LED Flat Panel Indicator

Dimensions (mm)

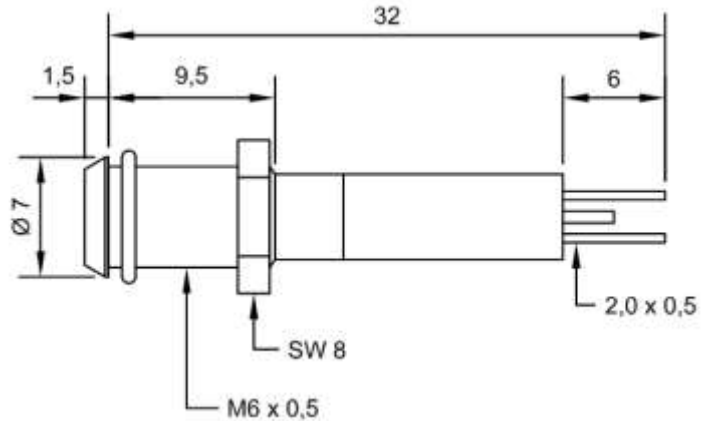

Part #	Colour	Current (mA)	Intensity (mcd)
1900X350	Red	15	2
1900X353	Super-Red	15	7
1900X351	Green	15	6
1900X352	Yellow	15	6

Notes:

- 1 X=Bezel chrome finish. 0=satin, 1=black, 2=matt
- 2 Electrical & optical data are measured at an ambient temperature of 25°C
- 3 Luminous intensity at DC
- 4 Storage temperature -25 °C to +80°C
- 5 Application temperature -20 °C to +60°C
- 6 Due to component tolerances, colour temperature variations may be observed
- 7 Ingress rating IP40
- 8 RoHS & REACH SVHC compliant