

# Master-slave PRO permanent socket strip 5+2-fold with overvoltage protection (type G)

Item-no.: 0215x0607830b-1 (1,5 m cord)



Robust plastic, grey

Built-in sockets (90° rotated), quadrangular

1,5 m power cord and angle plug (optional with 3 m or 5 m power cord)

1 blue master socket, 4 black slave sockets and 2 white permanent sockets

Automatic electronic switching M/S with precisely adjustable switching threshold


Optical function display for M/S function

Acoustic fault message in case of overvoltage protection according to EN 61643-11 type 3

EHMANN advantage - the connected devices will remain in operation after release of overvoltage protection


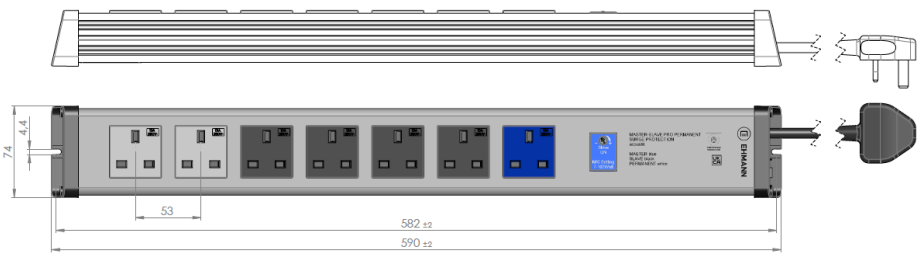
Expanded contact protection by using a shutter

End caps with mounting possibility and spare fuse

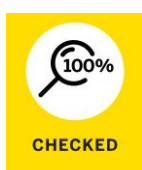

## Master-slave PRO permanent socket strip 5+2-fold with overvoltage protection (type G)

### Technical data

3.600 W Power	230 V ~ (+/- 10%) / 50 Hz Rated voltage	16 A Rated current	
<p>Power cord: H05VV-F 3G 1,5 mm<sup>2</sup></p> <p>Plug: BP1 British Standard Type G, BS 1363/A, angled</p> <p>Sockets: type G</p> <p>Voltage U<sub>n</sub>: 230 V~</p> <p>Max. continuous operation voltage U<sub>c</sub>: 255 V~</p> <p>U<sub>oc</sub>: 5000 V</p> <p>Protection level Up: L-N &lt; 1,0kV - L/N-PE &lt; 1,5kV</p> <p>I<sub>max</sub> (8/20): 6,5 kA</p> <p>Fuse: T6,3AH/250 V</p> <p>SPD according to EN 61643-11: Type 3</p> <p>Precise switching threshold: 7-100 W (master)</p> <p>Consumption: &lt; 0,6 W</p> <p>Consumption overvoltage protection: &lt; 0,1 W</p> <p>Safety class: IP20</p>			
 <p>(similar illustration)</p>			
Item-no. 0215x0607830b-1	EAN4012096011033	PU 10	590 x 74 x 45 mm Dimensions (L x W x H) 582 mm Fixing dimension