

DELTA FLAT IP44,
SM DARK GRAY/LIGHT GRAY SCHUKO OUTLET 2FOLD
HORIZONTAL,
10/16A 250V W. SCREWLESS TERMINALS W. HINGED
LID,
75X134MM



Similar to image

Technical data:

Product component / Error current protection	No
Product function / Socket selectable	No
Product function / Overvoltage protection	No
Product component / Ejection equipment	No
Product component / Child protection	No
Product component / Hinged lid	Yes
Product component / [nicht versorgt - Feinsicherung]	No
Product component / Lettering field	No
Product component / integrated / Fluorescent materials	No
Design of the product	SCHUKO
Design of the electrical connection	plug terminal
Design of the special power supply unit	without special current supply
Version de la prise de courant / selon VDE 0620 pour conditions difficiles	No
Caractéristique produit / verrouillable	No
Design of the cover	complete enclosure
Material	others
Appearance	shiny

Number of units		2
Type of mounting		surface mounted
Color		grey
Surface processing		others
Product feature / halogen-free		Yes
order of contacts / diagonal		No
Labeling / [nicht versorgt - der Steckdose]		without imprint
Operating current / [nicht versorgt - Nennwert]	A	16
Operating frequency	Hz	50 ... 50
Operating voltage / nominal value	V	250
material / of the housing		plastic
Protection class IP		IP44
type of the assembly		fixing with screw

Further information:

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Global Industry Mall (Online ordering system)

<http://www.siemens.com/lowvoltage/mall>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)


<http://support.automation.siemens.com/WWW/view/en/5UB4722/all>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)

http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=5UB4722

Tender specifications

[Datanorm GAEB81](#) [GAEB83](#) [RTF](#) [TXT](#)

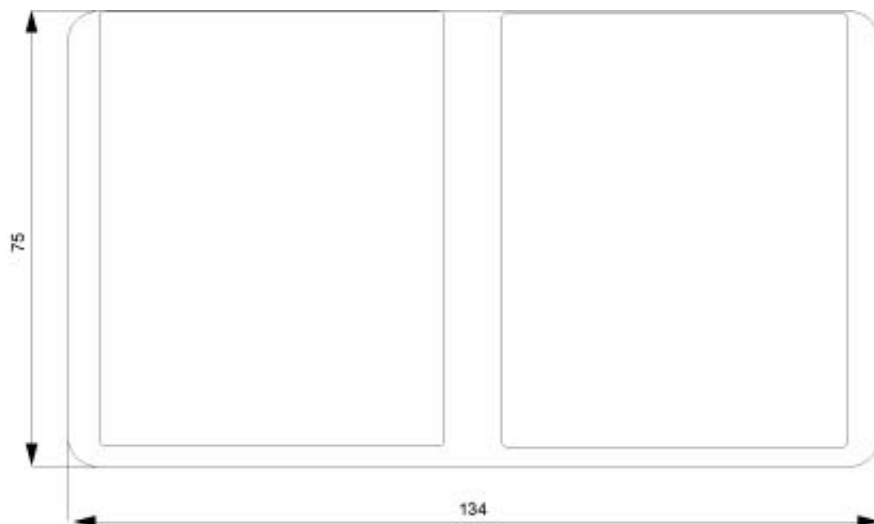

last change:

Dec 6, 2010