



Product Compliance


[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant with Exemptions
EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2022 (223) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Also in the Series | ELCON Drawer

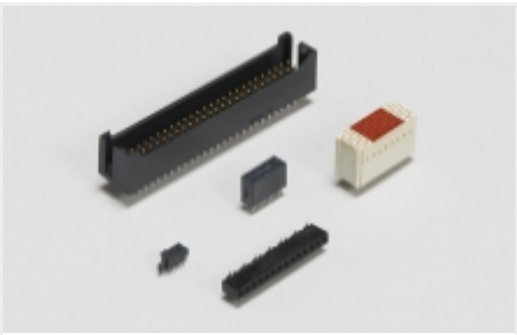

Board-to-Board Headers & Receptacles(25)



Connector Contacts(34)

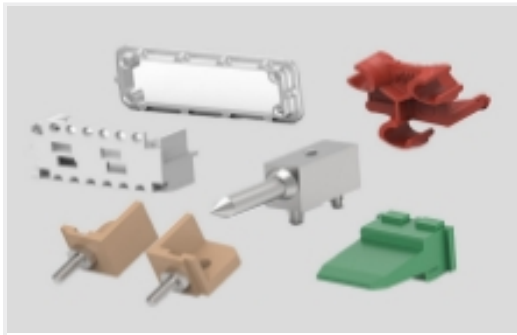

Connector Hardware(1)



Power Contacts(34)



Rectangular Connector Housings(1)




Rectangular Power Connectors(24)



Standard Rectangular Connectors(2)

Customers Also Bought

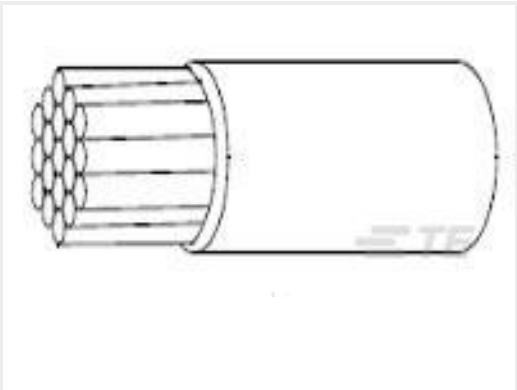

TE Part #216278-001
22759/33-24-9



TE Part #YDTS26W15-18SNV001
PLUG ASSY



TE Part #5788801-1
25 HTMSFL ASSY RA 318 (SL,BL)




TE Part #1-794229-0
MINI UMN2 SOK 22-18AWG LP LF




TE Part #1650156-2
701-15-02109=CONTACT,PIN,#12



TE Part #1617125-6
JMAW-26XM = M39016/9-018M

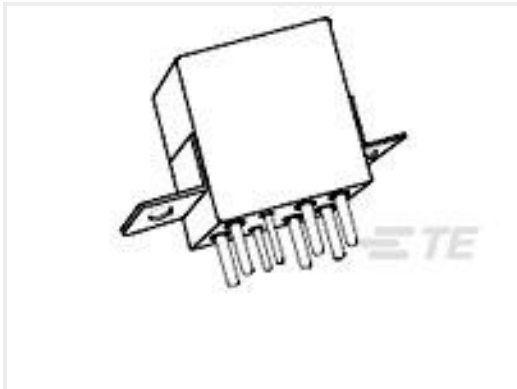

TE Part #2-1617749-2
FCA-210-1024M=M83536/10-024M

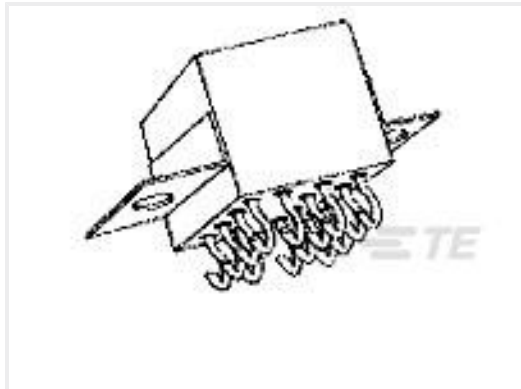

TE Part #8-1617760-5
FCB-405-0624M=M83536/6-024M



TE Part #1648552-1
295-0049-01100

Documents



Product Drawings

CONTACT,PIN,SIZE #0

English

CAD Files

Customer View Model

ENG_CVM_1766269-1_B.3d_igs.zip

English

Customer View Model

ENG_CVM_1766269-1_B.3d_stp.zip

English

Customer View Model

ENG_CVM_1766269-1_B.2d_dxf.zip

English

3D PDF

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

POWER_CONNECTORS_CATALOG_SEC02_CABLE_MOUNTED

English

AMP & ELCON Power Connector Layout Forms Datasheet 6-1773444-7

English

Product Specifications

Application Specification

English