


## Radial insert ball bearings UC208-24

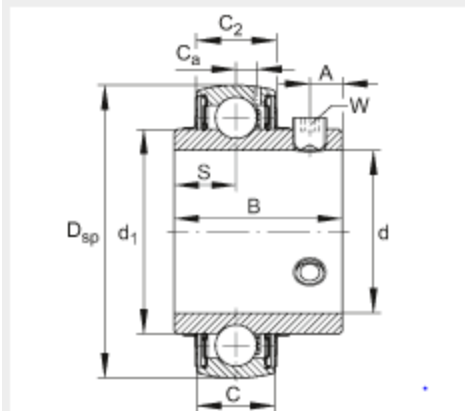

d	38,1 mm	
d	1 1/2 inch	
D <sub>SP</sub>	80 mm	
B	49,2 mm	
A	8 mm	
C	21 mm	
C <sub>2</sub>	21,6 mm	
C <sub>a</sub>	6,2 mm	
d <sub>1</sub>	52,27 mm	
S	19 mm	
W	5/32 inch	
m	0,66 kg	Mass
C <sub>r</sub>	34500 N	Basic dynamic load rating, radial
C <sub>0r</sub>	19800 N	Basic static load rating, radial