

## Lynx-L

LYNX-L 36W/840 10-WAY

0025658



### Range features



### PRODUCT OVERVIEW

Ordering number	0025658
Light colour	840
Technology	Compact Fluorescent
Energy class	A
Average life (Rated) (h)	16000
Lamp shape	Stick
Dimmable	Referring to ballast
Cap/Base	2G11
Type	Lynx L
EAN code	5410288256580
CRI (Ra)	82
Colour temperature (K)	4000
Luminous flux (Rated) (lm)	2950
Efficacy (Rated) (lm/w)	81
Watt (Nominal) (W)	36
Voltage (V)	106

## Lynx-L

LYNX-L 36W/840 10-WAY

0025658

### DATA TABLE

#### General data

Technology	Compact Fluorescent
Ordering number	0025658
Average life (Rated) (h)	16000
Average life (Nominal) (h)	16000
Energy class	A
Lamp shape	Stick
Dimmable	Referring to ballast
Cap/Base	2G11
Type	Lynx L
EAN code	5410288256580
E-number FI	4943884
Product name	LYNX-L 36W/840 10-WAY
Lamp mercury content (mg)	<3.0
Starting time (max) (s)	<10
Warm-up time to 60% of full light (max) (s)	60
Control gear required	Yes
IEC Reference	IEC 60901
IEC Reference 2	IEC 61199
Intended purpose	General lighting
Special purpose lamp	No
Transformer required	Managtic ballast
Sales pack quantity	10
Rated survival factor at 2000 h 50Hz	0.98
Rated survival factor at 4000 h 50Hz	0.9
Rated survival factor at 6000 h 50Hz	0.85
Rated survival factor at 8000 h 50Hz	0.8
Rated survival factor at 12000 h 50Hz	0.78
Rated survival factor at 16000 h 50Hz	0.5

## Lynx-L

LYNX-L 36W/840 10-WAY

0025658

### Optical data

Light colour	840
CRI (Ra)	82
Colour temperature (K)	4000
Luminous flux (Rated) (lm)	2950
Luminous flux (Nominal) (lm)	2950
Ambient temperature for maximum luminous flux (°C)	25
Rated lumen maint. factor at 2000 h 50Hz	8500%
Rated lumen maint. factor at 4000 h 50Hz	7800%
Rated lumen maint. factor at 6000 h 50Hz	7600%
Rated lumen maint. factor at 8000 h 50Hz	7500%
Rated lumen maint. factor at 12000 h 50Hz	73
Rated lumen maint. factor at 16000 h 50Hz	70

### Electrical data

kWh per 1000 hours burning time	40
Efficacy (Rated) (lm/w)	81
Watt (Rated) (W)	36
Watt (Nominal) (W)	36
Voltage (V)	106
Ignition voltage (V)	198
Current (A)	0.435

### Physical data

Weight (kg)	0.12
Length base to base (mm) - A	No
Lamp Length (mm) - C/L	417.4
Single packaging type	Box/Sleeve
Single package dimensions (L x W x H) (cm)	43.20 x 4.50 x 2.50
Inner package dimensions (L x W x H) (cm)	44.20 x 10.00 x 14.00
Inner package net weight (kg)	1.20
Outer package dimensions (L x W x H) (cm)	53.00 x 46.50 x 16.50


## Lynx-L

LYNX-L 36W/840 10-WAY

0025658

### TECHNICAL DRAWINGS

2G11

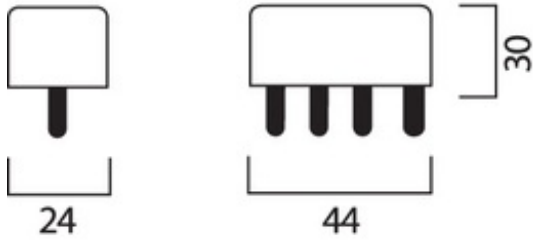

### ENERGY LABEL

