

### Features

- Strong and durable nylon base and zinc plated steel threaded rod
- Integrated hex nut in threaded rod to adjust height
- 20 degrees of articulation

### **RS PRO Adjustable Levelling Foot, Nylon Base, 50mm Diameter, M10x70mm Zinc Plated Steel Thread**

RS Stock No.: 0285758



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.


## Product Description

A glass-reinforced nylon base and zinc plated steel threaded rod. Height adjustment is achieved by an integrated hex nut in the threaded rod. An industry standard 15mm ball and socket provides 20° of articulation from perpendicular. The glass reinforced plastic base is tough and lightweight, while the zinc plated rod offers sufficient corrosion resistance for most indoor applications.

## General Specifications

<b>Diameter</b>	50mm
<b>Thread</b>	M10x70mm
<b>Material</b>	Nylon and zinc plated steel
<b>Colour</b>	Black
<b>Application</b>	Various types of furniture, processing and packaging machinery and equipment, lathes, milling machines and conveyors

<b>A</b>	50
<b>B</b>	29
<b>C</b>	18
<b>Thread size</b>	M10
<b>Thread length</b>	70
<b>Maximum load</b>	470kg

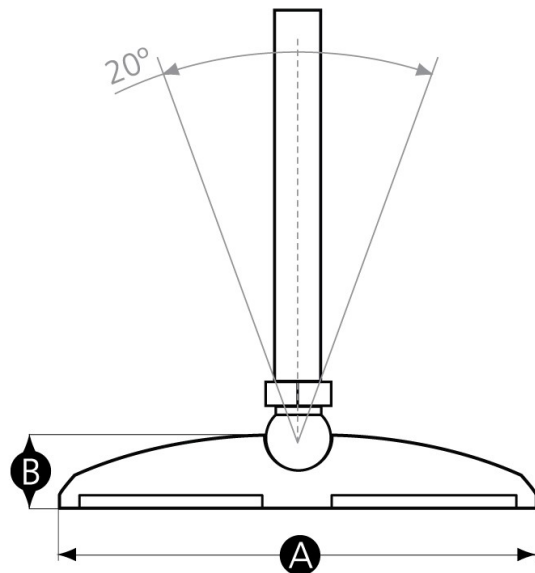

Stock No.	Brand	Product Name	Diameter	Thread size
0285750	RS PRO	Nylon Adjustable foot	40mm	M8x25mm
0285751	RS PRO	Nylon Adjustable foot	40mm	M8x40mm
0285752	RS PRO	Nylon Adjustable foot	50mm	M8x40mm
0285754	RS PRO	Nylon Adjustable foot	50mm	M8x60mm
0285755	RS PRO	Nylon Adjustable foot	50mm	M8x80mm
0285757	RS PRO	Nylon Adjustable foot	50mm	M10x45mm
0285758	RS PRO	Nylon Adjustable foot	50mm	M10x70mm
0285760	RS PRO	Nylon Adjustable foot	50mm	M10x90mm
0285761	RS PRO	Nylon Adjustable foot	60mm	M10x125mm
0285763	RS PRO	Nylon Adjustable foot	60mm	M10x45mm
0285764	RS PRO	Nylon Adjustable foot	60mm	M10x70mm
0285766	RS PRO	Nylon Adjustable foot	60mm	M12x66mm
0285767	RS PRO	Nylon Adjustable foot	60mm	M12x80mm
0285768	RS PRO	Nylon Adjustable foot	60mm	M12x100mm
0285770	RS PRO	Nylon Adjustable foot	60mm	M12x125mm
0285772	RS PRO	Nylon Adjustable foot	60mm	M12x150mm
0285773	RS PRO	Nylon Adjustable foot	80mm	M12x66mm
0285774	RS PRO	Nylon Adjustable foot	80mm	M12x100mm
0285776	RS PRO	Nylon Adjustable foot	80mm	M16x66mm
0285777	RS PRO	Nylon Adjustable foot	80mm	M16x100mm
0285779	RS PRO	Nylon Adjustable foot	80mm	M16x150mm
0285780	RS PRO	Nylon Adjustable foot	80mm	M20x100mm
0285782	RS PRO	Nylon Adjustable foot	80mm	M20x150mm
0285783	RS PRO	Nylon Adjustable foot	100mm	M16x66mm
0285785	RS PRO	Nylon Adjustable foot	100mm	M16x150mm
0285786	RS PRO	Nylon Adjustable foot	120mm	M20x150mm