


Features

- **Material:** Nylon 66
- **Color:** Natural (
- **Flame Retardant Rating:** UL94V-2
- **Operating Temperature Range:** Up to 85°C (185°F)

RS PRO Cable Ties

RS Stock No.: 0603221

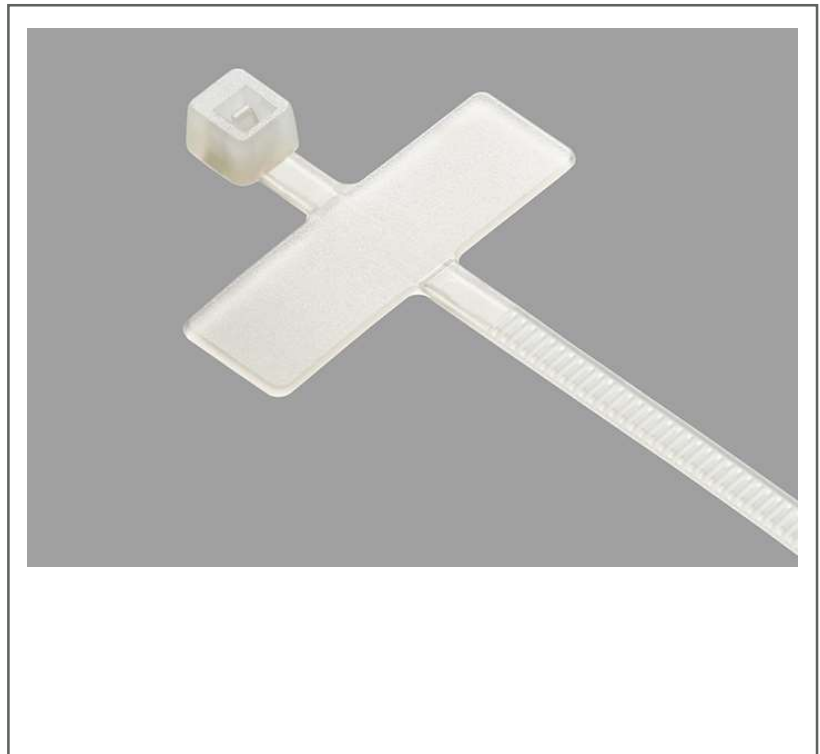

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

Simplify your cable management and identification needs with a high-quality cable tie designed to provide secure bundling and easy labelling in one efficient solution.

Key Features

- **Integrated Label Design:** Includes a writable label for clear identification of cables, wires, or bundled components.
- **Durable Construction:** Made from Polyamide (Nylon 66), ensuring strength, flexibility, and longevity.
- **Heat Resistance:** Operates effectively in temperatures up to 85°C (185°F).
- **Flame Retardant:** Rated UL94V-2 for safety and reliability in various environments.
- **Maximum Bundle Diameter:** Accommodates bundles up to 25 mm.
- **Natural Colour:** Clean, professional appearance in white that complements most setups.

General Specifications

Series	Marker Ties
Type	Non-Releasable
Colour	Natural
Material	Nylon 66
Finish	N/A
Application	Bundling wire together / Tightening labels to poles
UV Resistant	No
Minimum Operating Temperature	-28°C
Maximum Operating Temperature	85°C
Fire Behaviour	Self-Extinguishing
Quantity	100

Mechanical Specifications

Length	100mm
Width	2.5mm
Tensile Strength	80N
Maximum Bundle Diameter	23mm