




Datasheet

RS PRO REINFORCED GARDEN HOSE - GH SERIES

Stock number: See Table

EN

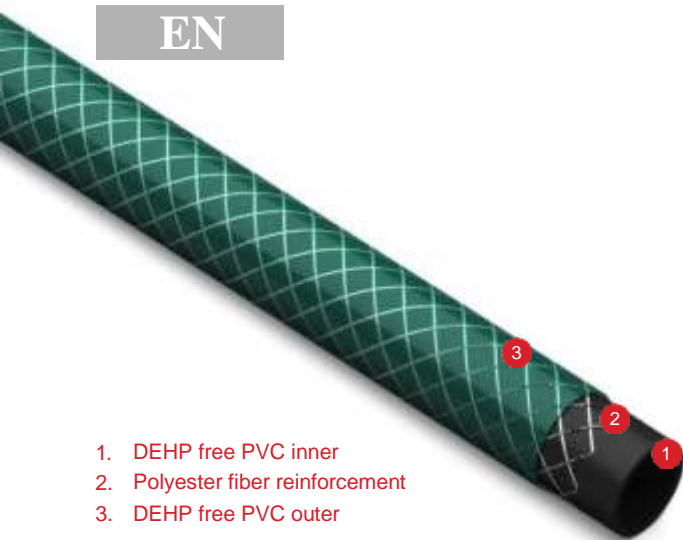

- 1. DEHP free PVC inner
- 2. Polyester fiber reinforcement
- 3. DEHP free PVC outer

This reinforced garden hose is renowned for its flexibility, performance and reliability. The design incorporates durable reinforcement technology for a longer lifespan. Made in the UK – you can trust that the hose has been made from higher quality materials, under better conditions, and with superior workmanship to those imported from Asia.

Key Features:

 
- Flexible and easy to handle.
- Effective kink resistance.
- Good abrasion resistance.
- Made from Cadmium-free materials.
- Silicone-free.
- Suitable for use at -15°C to +60°C.
- Specially selected high tensile Polyester fiber reinforcement used at the optimum braid angle of 54° 44' (54.73°) creates an effectively balanced pressure hose.
- Conforms to BS 3746: 1990.
- RoHS 3 compliant.
- REACH compliant.

Sizes:

Available in 15m, 30m and 50m coils.
Also available as part of spray gun set.
12mm.

Colour:

Transparent green outer
with black inner



Product Ref	Length	Internal Diameter	Maximum Working Pressure	Minimum Burst Pressure	Spray Gun Fitted	Weight per coil
2020988	15m	12mm	10 Bar	30 Bar		1.97 Kg
330-0858	30m	12mm	10 Bar	30 Bar		3.95 Kg
330-0870	50m	12mm	10 Bar	30 Bar		6.58 Kg
2020989	15m	12mm	10 Bar	30 Bar	✓	1.97 Kg
2020990	30m	12mm	10 Bar	30 Bar	✓	3.95 Kg
2020991	50m	12mm	10 Bar	30 Bar	✓	6.58 Kg