


Geberit Mapress Stainless Steel bend with plain end (FKM, blue)

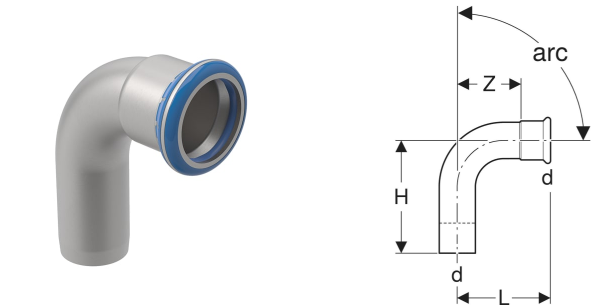

Example image

APPLICATION PURPOSES

- For chemicals and technical liquids
- For district heating water ≤ 140 °C
- For thermal media (solar)
- For mineral and lubricating oil
- For motor fuels (e.g. diesel)

- For compressed air (oil purity class 0–4)
- For solar technology, industry and shipbuilding
- For industrial gases (e.g. acetylene, shielding gases)

- Silicone-free (LABS-free)
- Seal ring made of FKM, blue
- Pressing socket with black protection plug

CHARACTERISTICS

- Pressing indicator

TECHNICAL DATA

Product material CrNiMo steel 1.4401 (EN 10088)

Art. no.	DN	d, ø mm	arc °	L cm	H cm	Z cm
50242	12	15	45	2.8	3.6	0.8
50243	15	18	45	2.9	3.6	0.9
50244	20	22	45	3.2	4	1.1
50245	25	28	45	3.7	4.4	1.4
50246	32	35	45	4.3	5	1.7

Art. no.	DN	d _ø mm	arc °	L cm	H cm	Z cm
50247	40	42	45	5.1	5.9	2.1
50248	50	54	45	6.2	7	2.7
50251	65	76.1	45	10.1	11.1	4.8
50252	80	88.9	45	11.7	12.8	5.7
50253	100	108	45	14.3	15.8	6.8
50312	12	15	90	3.8	4.8	1.8
50313	15	18	90	4.2	5.1	2.2
50314	20	22	90	4.7	5.8	2.6
50315	25	28	90	5.7	6.3	3.4
50316	32	35	90	6.8	7.4	4.2
50317	40	42	90	8	8.8	5
50318	50	54	90	10	10.8	6.5
50321	65	76.1	90	15.7	16.7	10.4

Art. no.	DN	d _ø mm	arc °	L cm	H cm	Z cm
50322	80	88.9	90	18.4	19.5	12.4
50323	100	108	90	22.6	24.1	15.1