 

 
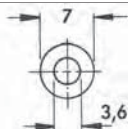


## Distance spacers


– special lengths on request



art. no.	C [mm]	art. no.	C [mm]	art. no.	C [mm]
<b>DR 071 V0</b>	1	<b>DR 079 V0</b>	9	<b>DR 725 V0</b>	25
<b>DR 072 V0</b>	2	<b>DR 710 V0</b>	10	<b>DR 730 V0</b>	30
<b>DR 073 V0</b>	3	<b>DR 711 V0</b>	11	<b>DR 735 V0</b>	35
<b>DR 074 V0</b>	4	<b>DR 712 V0</b>	12	<b>DR 740 V0</b>	40
<b>DR 075 V0</b>	5	<b>DR 713 V0</b>	13	<b>DR 745 V0</b>	45
<b>DR 076 V0</b>	6	<b>DR 714 V0</b>	14	<b>DR 750 V0</b>	50
<b>DR 077 V0</b>	7	<b>DR 715 V0</b>	15	<b>DR 760 V0</b>	60
<b>DR 078 V0</b>	8	<b>DR 720 V0</b>	20		

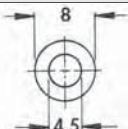

art. no.	C [mm]	art. no.	C [mm]	art. no.	C [mm]
<b>DR 081 V0</b>	1	<b>DR 089 V0</b>	9	<b>DR 825 V0</b>	25
<b>DR 082 V0</b>	2	<b>DR 810 V0</b>	10	<b>DR 830 V0</b>	30
<b>DR 083 V0</b>	3	<b>DR 811 V0</b>	11	<b>DR 835 V0</b>	35
<b>DR 084 V0</b>	4	<b>DR 812 V0</b>	12	<b>DR 840 V0</b>	40
<b>DR 085 V0</b>	5	<b>DR 813 V0</b>	13	<b>DR 845 V0</b>	45
<b>DR 086 V0</b>	6	<b>DR 814 V0</b>	14	<b>DR 850 V0</b>	50
<b>DR 087 V0</b>	7	<b>DR 815 V0</b>	15	<b>DR 860 V0</b>	60
<b>DR 088 V0</b>	8	<b>DR 820 V0</b>	20		

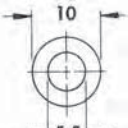

art. no.	C [mm]	art. no.	C [mm]	art. no.	C [mm]
<b>DR 105 V0</b>	5	<b>DR 125 V0</b>	25	<b>DR 140 V0</b>	40
<b>DR 110 V0</b>	10	<b>DR 130 V0</b>	30	<b>DR 145 V0</b>	45
<b>DR 115 V0</b>	15	<b>DR 135 V0</b>	35	<b>DR 150 V0</b>	50
<b>DR 120 V0</b>	20				

<b>material:</b>	polyamide
<b>heat distortion:</b>	180°C
<b>temperature range:</b>	+180°C
<b>colour:</b>	black
<b>class of flammability:</b>	UL 94 V-0