 



vacuum security valve ISV-M10

Part number: 545998

FESTO

For maintenance of vacuum if one or more suction cups within a group fail to make contact with the workpiece.

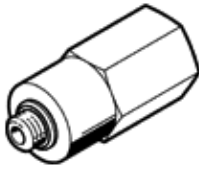

Data sheet

Feature	Value
Size	M10
Ejector pulse suitability	≤ 8 bar
Assembly position	Any
Operating pressure	-0.95 ... 0 bar
Required suction rate at -0.5 bar	2 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Ambient temperature	-10 ... 60 °C
Product weight	18 g
Mounting type	Threaded
Pneumatic connection, port 1	M10
Pneumatic connection, port 2	M10
Material spring	High alloy steel
Material filter	Sintered bronze
Material housing	Wrought Aluminium alloy
Material float	POM