

FEATURES

- Very reliable
- Very sturdy
- Easy to fit
- Good short time rating
- Easy to move tapping clip
- Comes complete with mounting brackets

RS PRO

RS Stock No.: 2383226



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

ADJUSTABLE WIRE WOUND RESISTORS

Product Description

RS PRO Vitreous Enamelled Resistors are available in a range from 90 Watts to 750 Watts.

The Nickel-Chrome winding is completely protected by several coats of vitreous enamel, which have been fired to produce a high reliability resistor, capable of withstanding adverse conditions.

Resistors are supplied with terminal tags suitable for screws, or on some sizes, for 'Faston' terminals.

Terminal bands are spot welded in position on the heat resistant ceramic former, and the winding in turn spot welded to the terminal before the enamelling process. The terminal bands are therefore an integral part of the resistor, protected by the vitreous coating

Comes complete with an adjustable tapping clip

General Specifications


Wire wound resistor, rated at 180 watts, adjustable between 0 – 470 Ohms

Electrical Specifications

Rated at 180 watts @ 470 OhmS

Additional Information

Custom Tariff Number 8533 3900

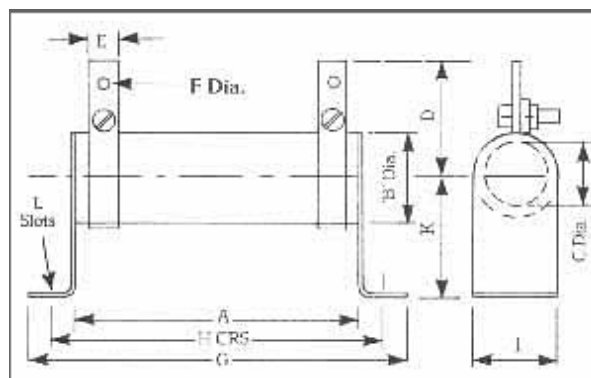

A	B	C	D	E	F	G	H	HR	J	K	R
216	32	19	37	9.5	6	256	240	194	28	27/40/65	5x13

