


Axial kit
EAMM-A-X48-87A
Part number: 8210061

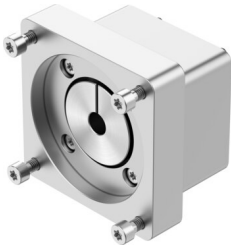

 [General operating condition](#)

Data sheet

Feature	Value
Mounting position	Any
Max. rotational speed	6000 rpm
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Transmittable torque	17 Nm
Product weight	808 g
Interface code, actuator	X48
Interface code, motor in	87A
Note on materials	RoHS compliant