

Features

- Strong and durable zinc plated steel construction
- 120-degree opening angle
- Removable pin which allows quick and easy removal of the door giving improved access for maintenance
- Easy mounting via either metric bolts or rivets

RS PRO Hinges

RS Stock No.: 0335175



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description


Zinc plated steel hinge, pin and circlip. 120 degree opening angle. A removeable pin allows the door to be separated from the enclosure, giving improved access. The pin is secured with a circlip. Designed for use in industrial enclosures and cabinets.

General Specifications

Length	60mm
Material	Zinc plated steel
Opening angle	120 degrees
Colour	Grey
Application	Enclosures, HVAC, machinery, equipment, construction industry
Radial load (N)	350
Axial load (N)	778

Mechanical Specifications

A	60
B	-
C	42
D	60
E	-
F	-
G	-
H	6.5
I	12
J	24.5
K	42

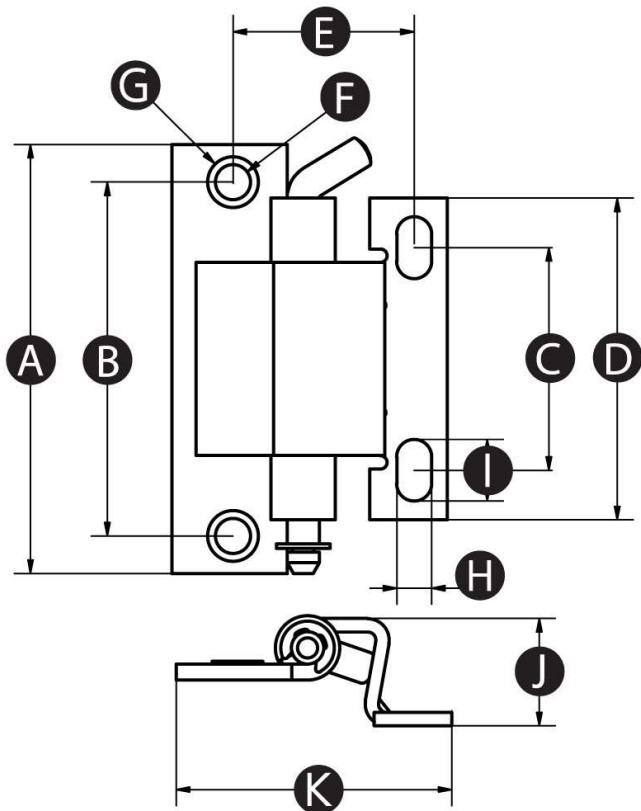

Similar Products

Stock No.	Brand	Product Name	Length	Opening Angle
0335183	RS PRO	Zinc Plated Steel Concealed Hinge	80mm	120 degrees
0335184	RS PRO	Stainless Steel Concealed Hinge	80mm	120 degrees
0335186	RS PRO	Zinc Plated Steel Concealed Hinge	80mm	120 degrees
0335153	RS PRO	Stainless Steel Concealed Hinge	80mm	120 degrees
0335180	RS PRO	Zinc Plated Steel Concealed Hinge	60mm	120 degrees
0335181	RS PRO	Stainless Steel Concealed Hinge	60mm	120 degrees
0335175	RS PRO	Zinc Plated Steel Concealed Hinge	60mm	120 degrees
0335177	RS PRO	Stainless Steel Concealed Hinge	60mm	120 degrees
0335178	RS PRO	Zinc Plated Steel Concealed Hinge	60mm	100 degrees