


Geberit Mapress Stainless Steel non-return valve, flanged

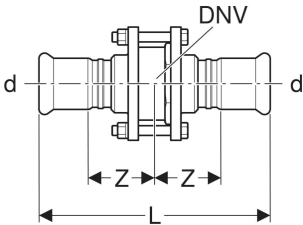

Example image

APPLICATION PURPOSES

- For cooling and heating water without antifreeze agent
- For cooling and heating water with antifreeze agent
- For district heating water ≤ 120 °C
- For service water and process water
- For treated water (application range according to Technical Information „Treated water“)

- For grey and black water with a pH value ≥ 5.5
- For extinguishing water (wet)

CHARACTERISTICS

- Valve seal made of PTFE
- Section seal of flange made of PTFE
- Pressing indicator

- Leaky if unpressed
- Seal ring made of CIIR, black
- Pressing socket with transparent protection plug

TECHNICAL DATA

Operating temperature	-20 – +120 °C
Product material	CrNiMo steel 1.4401 (EN 10088)

Art. no.	DN	DNV	d, ø mm	L cm	Z cm	PN bar
92140	12	15	15	11.1	3.8	40
92142	20	20	22	12	3.9	40
92143	25	25	28	12.6	4	16
92144	32	32	35	14.7	4.8	16
92145	40	40	42	16.7	5.3	16

<i>Art. no.</i>	<i>DN</i>	<i>DNV</i>	<i>d_ø</i> <i>mm</i>	<i>L</i> <i>cm</i>	<i>z</i> <i>cm</i>	<i>PN</i> <i>bar</i>
92146	50	50	54	18.5	5.8	16
92147	65	65	76.1	25.5	7.5	16
92148	80	80	88.9	28.5	8.3	16
92149	100	100	108	34.6	9.8	16