


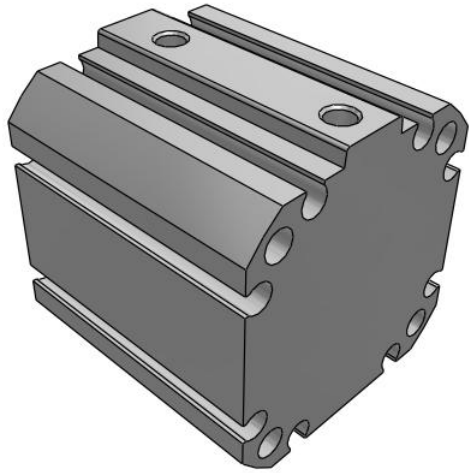



JC(D)Q, Compact Cylinder, Double Acting Single Rod JCDQ32-15

Datasheet

- Double acting, single rod, compact cylinder.
- Lightweight 25 g (ø12 stroke 5).
- Bore sizes (mm): 12 ~ 100.
- Strokes up to 50 mm.
- Bumper cushion.
- Auto switches can be mounted on 4 surfaces.

Magnet	D (Built-in)
Mounting	Through-hole (Standard)
Bore Size	32 mm
Port Thread Type	M thread: $\varnothing 12$ to $\varnothing 40$, Rc: 50 to 100
Stroke	15 mm
Auto Switch	No Switch
Lead Wire or Prewired Connector	0.5m (Or None in the Case of No Switch)
Number	2 pcs. (Or None in the Case of No Switch)
Pressure medium	Air
Maximum temperature of pressure medium	60 °C
Minimum temperature of pressure medium	5 °C
Maximum ambient temperature	60 °C
Minimum ambient temperature	5 °C
Conform to the European RoHS Directive	Conform
Numero of pneumatic connections	2 pcs.
Geometric form of the piston rod	Single rod
Weight	0.149 Kg

Dimensions

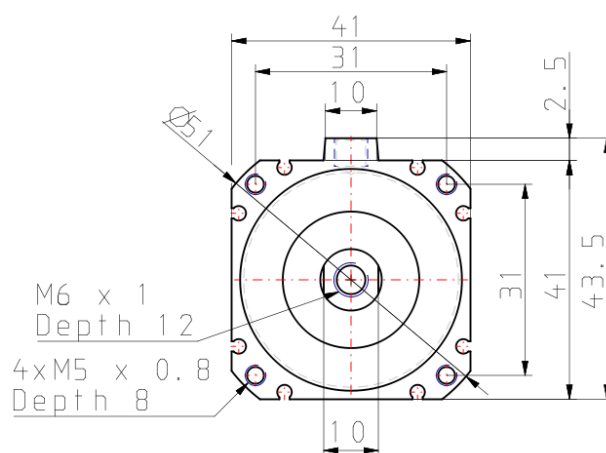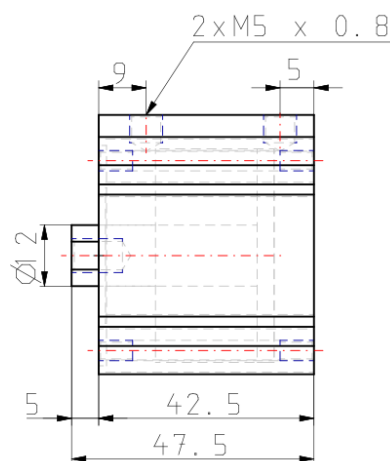

Additional information

Catalogue

[JCQ-C_EU.pdf](#)