

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130015-0033](#)
Status: **Active**
Overview: [Brad® Mini-Change® Connectors](#)
Description: Mini-Change® C-Size Receptacle with Leads 1/2" - 14 NPT Threads, Female (Straight), 10 Poles, 1.83m (6.0') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
UL E152210

General

Product Family Industrial Receptacles
Series [130015](#)
Comments C-Size (1-1/8" - 16 UN-2A)
IP Rating IP67
Overview [Brad® Mini-Change® Connectors](#)
Product Name Mini-Change®
Type Single Ended (pigtail)
UPC 78678834569

Physical

Coupling Type External Thread
Gender Female
Keyway Single
Length 1.83m
Material - Component Zinc Die-Cast with Black Epoxy
Mounting Thread Size 1/2" - 14 NPT
Net Weight 568.800/g
Orientation Straight
Panel Mount N/A
Poles 10
Temperature Range - Operating -20°C to +105°C
Wire Size AWG 16
Wire/Cable Type UL 1015

Electrical


Current - Maximum per Contact 7A
Voltage - Maximum 600V AC/DC

Material Info

Old Part Number 3R1004A20F060

Reference - Drawing Numbers

Sales Drawing SD-130015-005

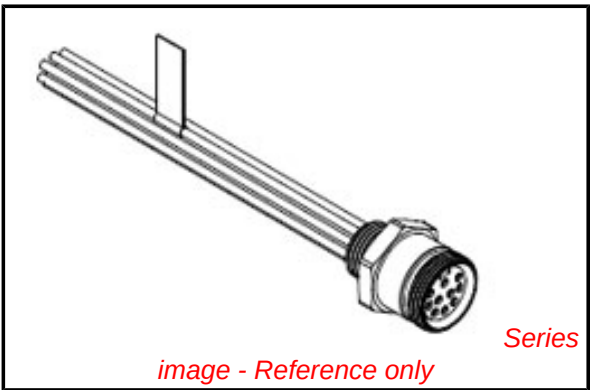

EU RoHS

RoHS Compliant by Exemption
REACH SVHC
Not Reviewed
Low-Halogen Status
Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[130015Series](#)