

J.17HLA | J.HLA - 3/8" LONG-REACH METRIC 6-POINT SOCKETS




Norm :


NF ISO 2725-1, NF ISO 1711-1, ISO 2725-1, ISO 1711-1, DIN 3124, ASME B107.5

Description :

- OGV® profile: more powerful tightening, preserves fasteners.
- Long-reach sockets for long recess or thread access.
- Available as rack set Ref JL.40E (7 --> 15 mm) and Ref RL.41E (16 --> 24 mm).
- Finish: bright chrome.

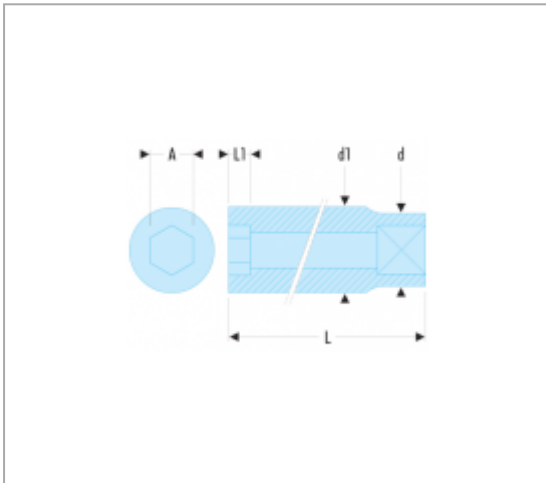

Informations :

	J.17HLA
A [mm]	17
d [mm]	22,0
d1 [mm]	23,5
L [mm]	60
L1 [mm]	15,0
Hex Size [mm]	6
[g]	102