


SUITABILITY	FEATURES / BENEFITS
<ul style="list-style-type: none"> Compressed Air 	<ul style="list-style-type: none"> Light and flexible Excellent resistance to oil, solvent and other non-aqueous solutions Excellent recoil ability and crimp resistance Long service life with outstanding ageing qualities Excellent abrasion resistance Available in 310, 315 & 410 series
SPECIFICATIONS	
Temperature range	-30°C to +60°C
Pressure rating	Values given are based on the short term burst pressure of CEJN PUR hose at 20°C using a 3:1 safety factor NOTE: Any increase in temperature above 20°C will result in a decline in the working pressure values
Construction	Spiral PUR. Ester-based, non braided polyurethane. Assembled with Stream-Line couplings, nipples and swivels

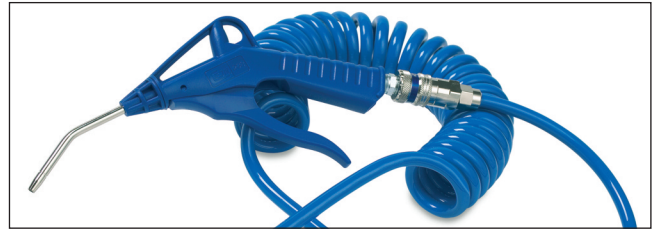

**CEJN PUR HOSE KITS
SERIES 320 SPIRAL**

285

PART NUMBER	mm	mm	mm	Bar
C199589907	5.0	8.0	2	10
C199589910	6.5	10.0	2	10
C199589914	8.0	12.0	2	10
C199589917	11.0	16.0	2	10
C199589903	5.0	8.0	4	10
C199589904	6.5	10.0	4	10
C199589905	8.0	12.0	4	10
C199589906	11.0	16.0	4	10
C199589908	5.0	8.0	6	10
C199589912	6.5	10.0	6	10
C199589915	8.0	12.0	6	10
C199589918	11.0	16.0	6	10
C199589909	5.0	8.0	8	10
C199589913	6.5	10.0	8	10
C199589916	8.0	12.0	8	10
C199589919	11.0	16.0	8	10

**CEJN HOSE KITS WITH BLOWGUN
STANDARD KIT - 320 Nipple, 1/4"**

285

PART NUMBER	mm	mm	mm	Blowgun
C1995899871	5.0	8.0	4	Standard
C1995899872	5.0	8.0	4	Star-tip
208 BLOWGUN - REMOVABLE TUBE - 320 Nipple, 1/4"				
C1995899654	6.5	10.0	2	Star-tip
208 BLOWGUN - REMOVABLE TUBE - 1/4", 1/4" swiveling				
C1995899671	5.0	8.0	6	Standard
NIPPLE ON LONG HOSE END - 1/4", 320 Nipple				
C1995899639	6.5	10.0	4	Standard
NIPPLE ASSEMBLED ON BLOWGUN - 320 Nipple & Coupling				
C1995899901	6.5	10.0	4	Standard
C1995899746	6.5	10.0	4	Star-tip
C1995899760	6.5	10.0	6	Star-tip
C1995899761	6.5	10.0	6	Standard