


Sub-base
VABS-S7-BE-BS-G14-VDE2
 Part number: 8072668

FESTO

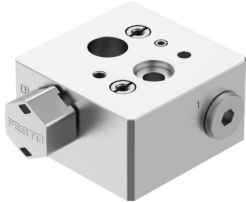

 [General operating condition](#)

Data sheet

Feature	Value
Mounting position	Any
Operating pressure	0 MPa ... 1 MPa
Operating pressure	0 bar ... 10 bar
Operating medium	Compressed air to ISO 8573-1:2010 [-:-:-]
Corrosion resistance class CRC	4 - Very high corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Degree of protection	IP54 IP65
Note on degree of protection	IP54 for exhaust protection with labyrinth (e.g. VABD-D3-L) IP65 for exhaust protection with sealing ring (e.g. VABD-D3-SN)
Product weight	362 g
Type of mounting	Via through-hole and screw
Pilot air port 12	G1/4
Pneumatic connection, port 1	G1/4
Pneumatic connection, port 2	VDI/VDE 3847 (NAMUR)
Pneumatic connection, port 3	G1/4
Note on materials	RoHS compliant
Material sub-base	Ematal coated aluminium
Material seals	NBR