



Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Customers Also Bought

TE Part #3-647476-9
09P MTA156 PSTD CONN 18AWG LF

TE Part #7-1437023-1
622-1431=FSKT IDC S 14 SR

TE Part #YDTS20F13-35HNV001
RECP ASSY

TE Part #641217-3
03P MTA156 CONN ASSY 18AWG ORA





TE Part #647476-9
[09P MTA156 PSTD CONN CE 18AWG](#)




TE Part #5-104439-4
[4X5 MTE RCPT SR PLAIN .100CL](#)




TE Part #3-647481-9
[09P MTA156 PSTD CONN 18AWG LF](#)



TE Part #306039-000
[44AM1121-18-9/96-9](#)

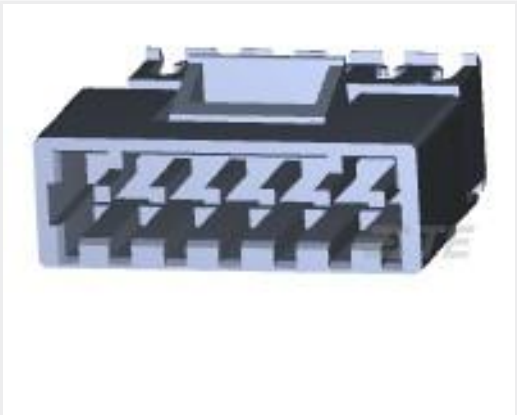

TE Part #3-647481-6
[06P MTA156 PSTD CONN 18AWG LF](#)

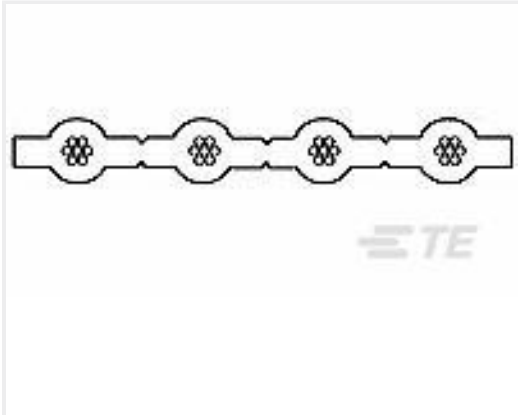

TE Part #57744-5
[Madison Spec 100-7244 Rev. 2](#)

Documents

Product Drawings

[2X7 MTE RCPT SR PLAIN .100CL](#)

English

CAD Files

[3D PDF](#)

3D

Customer View Model

[ENG_CVM_CVM_5-104439-6_P.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_5-104439-6_P.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_5-104439-6_P.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[AMP MODU MTE Section of Catalog 1307819](#)

English

[AMPMODU_INTERCONNECTION_SYSTEM_SECTION5_CONT](#)

English

[AMPMODU MTE INTERCONNECT SYSTEM](#)

English

Product Specifications



Application Specification

English