

# HOOK-UP WIRE


## HOOK-UP WIRE KITS

UL 1007/1569  
CSA TR-64  
MIL-W-76B, TYPE MW

### HOOK-UP WIRE KITS

Alpha's Hook-Up Wire Kits contain an assortment of 100 ft (30,5m) spools of hook-up wire suitable for military or UL/CSA applications. These kits have been designed for use by technicians, engineers and designers in the R & D lab or maintenance shop.

Each kit contains five spools of hook-up wire in a unique, rack-mounted, transparent dispensing tube. The tube and rack system keeps hook-up wire neat, clean and conveniently at hand.

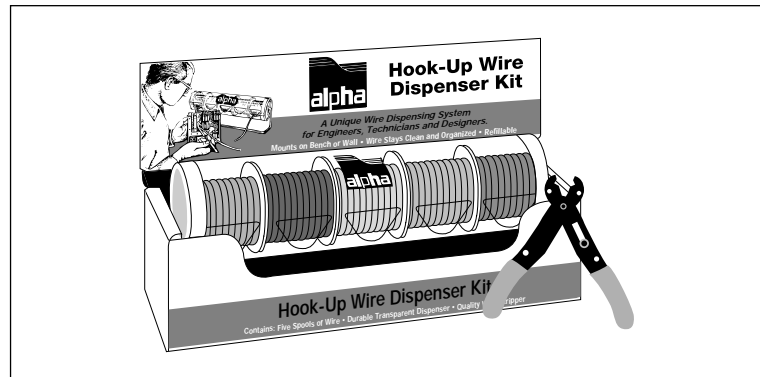

178

### CHOOSE HOOK-UP WIRE KITS FOR:

- Convenient, Wire Dispensing System
- Five Assorted Hook-Up Wire Colors
- Includes Cut and Strip Tool
- Uses Standard Alpha Hook-Up Wire Spools When Refills Are Required

### CHARACTERISTICS

#### OPERATING TEMPERATURE:

- -40°C to 80°C (HU-KIT-10, 30)
- -40°C to 105°C (HU-KIT-20, 40)

#### VOLTAGE RATING:

- 1000 Volt (HU-KIT-10, 30)
- 300 Volt (HU-KIT-20, 40)

#### PRODUCT DESCRIPTION:

- Conductor:  
Stranded Tinned Copper
- Insulation:  
Color-Coded PVC
- AWG Size:  
22 AWG (HU-KIT-10, 20)  
24 AWG (HU-KIT-30, 40)

### SPECIFICATIONS

- UL AWM Styles 1007 and 1569
- CSA TR-64
- MIL-W-76B, Type MW

Alpha Part No.	Contents	Quantity		Reorder No.
		Ft.	m	
HU-KIT-10 (22 AWG)	MIL-W-76B Type MW / White	100	30,5	1551
	MIL-W-76B Type MW / Black	100	30,5	1551
	MIL-W-76B Type MW / Red	100	30,5	1551
	MIL-W-76B Type MW / Green	100	30,5	1551
	MIL-W-76B Type MW / Blue	100	30,5	1551
	Cut and Strip Tool			

Alpha Part No.	Contents	Quantity		Reorder No.
		Ft.	m	
HU-KIT-20 (22 AWG)	UL 1007/1569, CSA TR-64 / White	100	30,5	3051
	UL 1007/1569, CSA TR-64 / Black	100	30,5	3051
	UL 1007/1569, CSA TR-64 / Red	100	30,5	3051
	UL 1007/1569, CSA TR-64 / Green	100	30,5	3051
	UL 1007/1569, CSA TR-64 / Blue	100	30,5	3051
	Cut and Strip Tool			

Alpha Part No.	Contents	Quantity		Reorder No.
		Ft.	m	
HU-KIT-30 (24 AWG)	MIL-W-76B Type MW / White	100	30,5	1550
	MIL-W-76B Type MW / Black	100	30,5	1550
	MIL-W-76B Type MW / Red	100	30,5	1550
	MIL-W-76B Type MW / Green	100	30,5	1550
	MIL-W-76B Type MW / Blue	100	30,5	1550
	Cut and Strip Tool			

Alpha Part No.	Contents	Quantity		Reorder No.
		Ft.	m	
HU-KIT-40 (24 AWG)	UL 1007/1569, CSA TR-64 / White	100	30,5	3050
	UL 1007/1569, CSA TR-64 / Black	100	30,5	3050
	UL 1007/1569, CSA TR-64 / Red	100	30,5	3050
	UL 1007/1569, CSA TR-64 / Green	100	30,5	3050
	UL 1007/1569, CSA TR-64 / Blue	100	30,5	3050
	Cut and Strip Tool			

 Recognized Component  
Underwriters Laboratories Inc.
  Passes UL VW-1 Flame Test  
Underwriters Laboratories Inc.
  Certified  
Canadian Standards Association



Toll Free: 1-800-52 ALPHA • Telephone: 908-925-8000 • Fax: 908-925-6923  
Europe/UK Telephone: +44 (0) 1932 772422 • Europe/UK Fax: +44 (0) 1932 772433

Web Site: [www.alphawire.com](http://www.alphawire.com)  
Email: [info@alphawire.com](mailto:info@alphawire.com)