




K7806M

**1/2" Square Drive Deep Impact
Sockets with Metric Hex Profile
and Phosphate Finish**



PRODUCT DETAILS



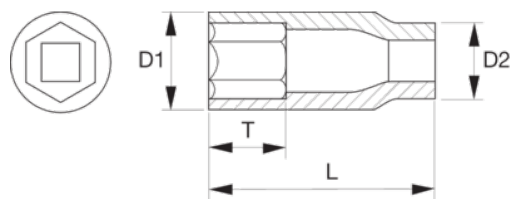




- To be used with machines
- For maximum safety use clamping springs
- Phosphate finish
- High-performance alloy steel
- Dynamic-Drive™ Profile to protect nuts, screws and tools from unnecessary wear and damage
- T = depth of female hexagon
- Drive standard: DIN 3121-G 12.5 ISO 1174



Follow the Fish!



PRODUCT ATTRIBUTES

Product							
K7806M-10	10 mm	78 mm	17.5 mm	25 mm	7.6 mm	K560F-4	215 g
SBK7806M-10	10 mm	78 mm	17,5 mm	25 mm	7,6 mm	K560F-4	215 g
K7806M-11	11 mm	78 mm	18 mm	25 mm	8.6 mm	K560F-4	150 g
SBK7806M-11	11 mm	78 mm	18 mm	25 mm	8,6 mm	K560F-4	150 g
K7806M-12	12 mm	78 mm	19.3 mm	25 mm	9.4 mm	K560F-4	215 g
SBK7806M-12	12 mm	78 mm	19,3 mm	25 mm	9,4 mm	K560F-4	215 g
K7806M-13	13 mm	78 mm	20.9 mm	25 mm	10.2 mm	K560F-4	160 g
SBK7806M-13	13 mm	78 mm	20,9 mm	25 mm	10,2 mm	K560F-4	160 g
K7806M-14	14 mm	78 mm	22.3 mm	25 mm	10.7 mm	K560F-4	170 g
SBK7806M-14	14 mm	78 mm	22,3 mm	25 mm	10,7 mm	K560F-4	170 g
K7806M-15	15 mm	80 mm	24 mm	29 mm	11 mm	K560F-5	300 g
SBK7806M-15	15 mm	80 mm	24 mm	29 mm	11 mm	K560F-5	300 g
K7806M-16	16 mm	78 mm	24.4 mm	30 mm	12 mm	K560F-5	320 g
SBK7806M-16	16 mm	78 mm	24,4 mm	30 mm	12 mm	K560F-5	320 g
K7806M-17	17 mm	78 mm	25.2 mm	30 mm	12.7 mm	K560F-5	240 g
SBK7806M-17	17 mm	78 mm	25,2 mm	30 mm	12,7 mm	K560F-5	240 g
K7806M-18	18 mm	78 mm	26.8 mm	30 mm	12.7 mm	K560F-5	260 g
SBK7806M-18	18 mm	78 mm	26,8 mm	30 mm	12,7 mm	K560F-5	260 g
K7806M-19	19 mm	78 mm	28.5 mm	30 mm	14 mm	K560F-5	260 g
SBK7806M-19	19 mm	78 mm	28,5 mm	30 mm	14 mm	K560F-5	260 g
K7806M-21	21 mm	78 mm	31.4 mm	30 mm	14.2 mm	K560F-5	280 g
SBK7806M-21	21 mm	78 mm	31,4 mm	30 mm	14,2 mm	K560F-5	280 g
K7806M-22	22 mm	78 mm	32.7 mm	30 mm	14.2 mm	K560F-5	390 g
SBK7806M-22	22 mm	78 mm	32,7 mm	30 mm	14,2 mm	K560F-5	390 g
K7806M-23	23 mm	78 mm	34 mm	30 mm	16.3 mm	K560F-5	490 g
SBK7806M-23	23 mm	78 mm	34 mm	30 mm	16,3 mm	K560F-5	490 g
K7806M-24	24 mm	78 mm	34.9 mm	30 mm	16.3 mm	K560F-5	340 g
SBK7806M-24	24 mm	78 mm	34,9 mm	30 mm	16,3 mm	K560F-5	340 g
K7806M-27	27 mm	78 mm	38.9 mm	30 mm	20.3 mm	K560F-5	400 g
SBK7806M-27	27 mm	78 mm	38,9 mm	30 mm	20,3 mm	K560F-5	400 g
K7806M-30	30 mm	78 mm	42.8 mm	30 mm	25.1 mm	K560F-5	430 g
SBK7806M-30	30 mm	78 mm	42,8 mm	30 mm	25,1 mm	K560F-5	430 g
K7806M-32	32 mm	78 mm	44 mm	30 mm	22 mm	K560F-5	460 g
SBK7806M-32	32 mm	78 mm	44 mm	30 mm	22 mm	K560F-5	460 g
K7806M-36	36 mm	78 mm	50.5 mm	27 mm	23 mm	K560F-5	570 g
SBK7806M-36	36 mm	78 mm	50,5 mm	27 mm	23 mm	K560F-5	570 g

Follow the Fish!



Contact: info@bahco.com / www.bahco.com