


Geberit Mapress Stainless Steel elbow adaptor 90° with female thread (silicone-free)



Example image

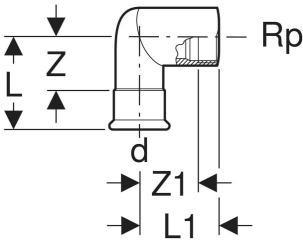

APPLICATION PURPOSES

- For cold and hot potable water
- For cooling and heating water without antifreeze agent
- For cooling and heating water with antifreeze agent
- For district heating water ≤ 120 °C
- For saturated steam ≤ 120 °C
- For service water and process water
- For treated water
- For grey and black water with a pH value ≥ 5.5
- For extinguishing water (wet)
- For extinguishing water (wet/dry, dry)

- For sprinklers (wet)
- For chemicals and technical liquids
- For compressed air (oil purity class 0–3)
- For negative pressure
- For inert gases (e.g. nitrogen)
- For industrial gases (e.g. acetylene, shielding gases)
- For technical building systems, industry and shipbuilding

- Seal ring made of CIIR, black

TECHNICAL DATA

Product material CrNiMo steel 1.4401 (EN 10088)

ACCESSORIES

- Fastening for Geberit Mapress elbow adaptor 90°

CHARACTERISTICS

- Pressing indicator
- Leaky if unpressed

Art. no.	DN	d, ø mm	Rp "	arc °	L cm	L1 cm	Z cm	Z1 cm
83803	12 / 15	15	1/2	90	5.7	3.7	3.7	2.4
83804	15	18	1/2	90	5.7	3.9	3.7	2.6
83805	20	22	3/4	90	6	4.6	3.9	3.1

<i>Art. no.</i>	<i>DN</i>	<i>d_ø</i> <i>mm</i>	<i>R_p</i> <i>"</i>	<i>arc</i> <i>°</i>	<i>L</i> <i>cm</i>	<i>L1</i> <i>cm</i>	<i>Z</i> <i>cm</i>	<i>Z1</i> <i>cm</i>
83806	25	28	1	90	6.7	5.4	4.3	3.7
83807	32	35	1 1/4	90	7.5	6.3	4.9	4.4