




THE ROUTE OF LEAST RESISTANCE

SEE NO EVIL

VAN DAMME ENHANCED PERFORMANCE UHD VISION 12GHZ CABLE RG6/U LSZH

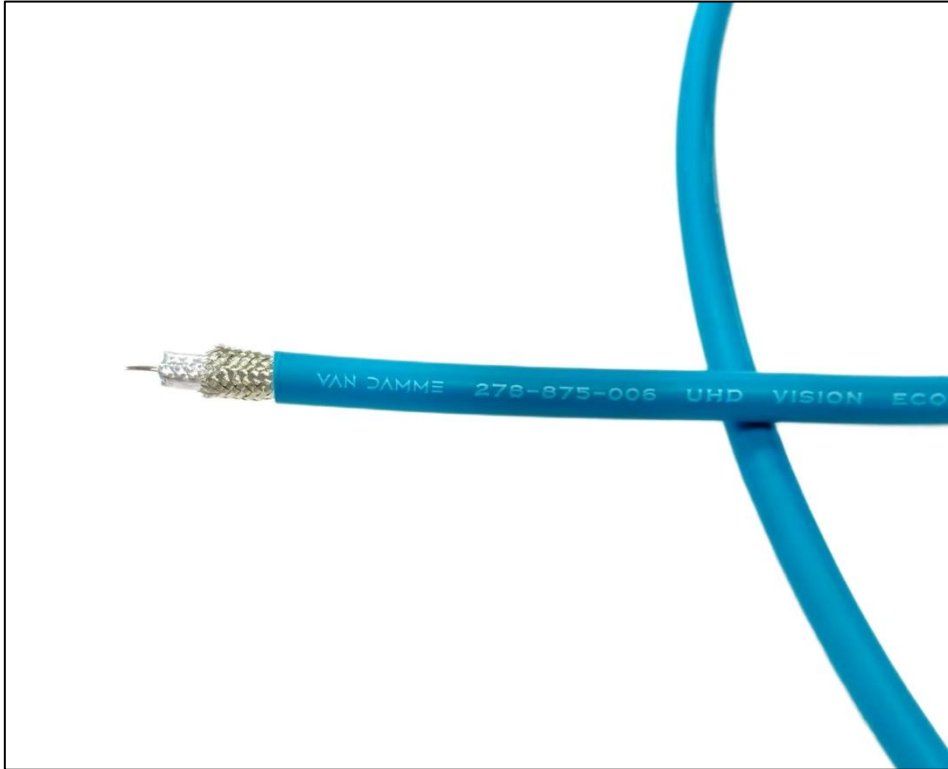

APPLICATIONS



Broadcast



Video



Presentations

MATERIALS



Oxygen free
copper



Skin Foam Skin
Polyethylene



LSZH Jacket

KEY BENEFITS



Precision 75
Ohm Impedance



Extended
Transmission
Length



CPR E_{ca}

Low Smoke Zero Halogen jacketed version of the Van Damme Enhanced Performance UHD 12G Vision coaxial, based around the industry standard RG6/U. Its precision construction ensures that electrical performance is optimised, ensuring trouble free performance with 4K Single-link 12 Gb/s UHD TV, SMPTE 424M and 292M HDSDI signals as well as SDI and analogue video. Designed for installation with an Eca CPR rating

www.van-damme.com

SEE NO EVIL

Applications

- Transmission of UHD, HD-SDI, SDI and analogue video signals
- SMPTE 2082-1 12 Gb/s UHD TV up to 72 metres
- SMPTE 2081-1 6 Gb/s UHD TV up to 103 metres
- Installation in Broadcast and Post Production facilities, public buildings, schools and colleges and government premises

Application Notes

- Use of precision 75 Ohm components throughout any signal chain is imperative
- See downloads for further transmission length guidelines

Mechanical Specification

Conductor	Silver plated oxygen free copper
Stranding	1 x 1.05 mm
Size	0.87 mm ² , AWG 18
Dielectric	Gas injected foam skin polyethylene
Diameter (mm)	4.60
Screen 1	Aluminium/polyester foil (bonded) > 115%
Screen 2	Tinned oxygen free copper braid > 95%
Overall jacket	LSZH polymer Water Blue RAL 5021
Overall diameter (mm)	6.95 ± 0.25
Bend radius	15 x overall diameter
Operating temperature	-30 to +75 °C

Electrical Specification

Conductor resistance (Ohm/km)	21
Capacitance (pF/m)	52
Impedance (Ohms)	75 ± 1.5
Velocity ratio	> 84.5%
Attenuation (dB/100m)	
100 MHz	6.20
135 MHz	6.80
180 MHz	8.00
270 MHz	10.00
720 MHz	16.00
1500 MHz	24.00
3000 MHz	35.00
4500 MHz	43.00
6000 MHz	50.00



SEE NO EVIL

Part Numbers and Description

Part Number	Description	Max. Reel Length
278-875-006	Van Damme Enhanced UHD Vision 12Ghz solid conductor coax RG6/U LSZH	500 m

Recommended BNC Connectors

339-675-300	Van Damme HD-SDI cable male RG6/U
339-675-312	Van Damme UHD 12G cable male RG6/U
	Neutrik rearTWIST HD BNC NBNC75BTU11
	Neutrik rearTWIST UHD BNC NBNC75BTU11X

Connector selection criteria:

Conductor	Dielectric diameter	Overall diameter	Summary
1 x 1.05 mm	4.60 mm	6.95 mm	(1.0/4.6/7.0)

Standards and Compliance

RoHS 3 (EU 2015/863)	Restriction of Hazardous Substances
REACH	Registration, Evaluation, Authorisation and Restriction of Chemicals
CPR Class	Eca