



Datasheet

ENGLISH

Stock No: 2674164

RS Pro FDFNYD1 Series Red Insulated Crimp Receptacle, 6.35 x 0.8mm, 20 → 16 AWG, Copper Plated



Product Details:



RS Pro Shrouded Female Receptacle Crimp Terminals A range of fully insulated or shrouded double crimp female receptacle terminals made from brass with a copper sleeved barrel and flared nylon insulation. These shrouded female receptacle crimp connectors are colour coded for use with different wire sizes and accept a variety of tab sizes. For suitable crimp tool please see stock number 267-3133.

- Red 0.5 - 1.5 mm²
- Blue 1 - 2.6 mm²
- Yellow 2.5 - 6.5 mm²

Approvals UL Listed

Specifications:

Tab Size:	6.35 x 0.8mm
Colour:	Red
Insulation:	Insulated
Wire Size:	20 → 16 AWG
Gender:	Female
Connector Type:	Quick Disconnect Terminal
Series:	FDNYD1
Contact Material:	Brass
Contact Plating:	Copper
Length:	21.5mm
Insulation Material:	Nylon

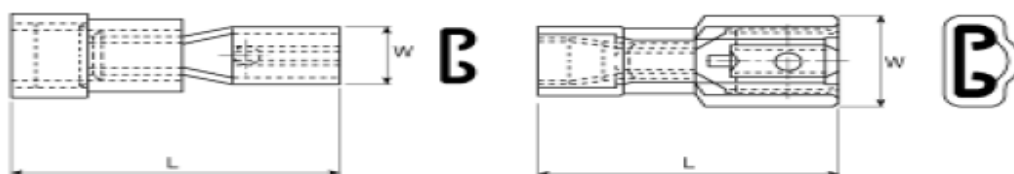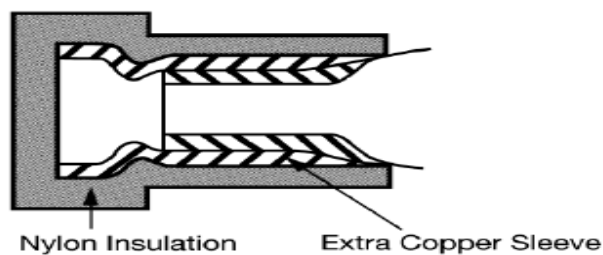

Type	Unshrouded						Shrouded					
	Red		Blue		Yellow		Red		Blue		Yellow	
	W	L	W	L	W	L	W	L	W	L	W	L
Size A	6.6	20.0	6.6	20.7	6.6	23.0	9.4	21.5	9.4	21.5	9.4	24.2
Size B	4.9	19.2	4.9	19.2			7.4	19.2	7.4	20.2		
Size C	5.0	19.2	5.0	19.2			7.4	19.2	7.4	20.2		
Size D	3.2	19.2					5.8	19.2				
Size E	3.2	19.2					5.8	19.2				