


PHE L070NR

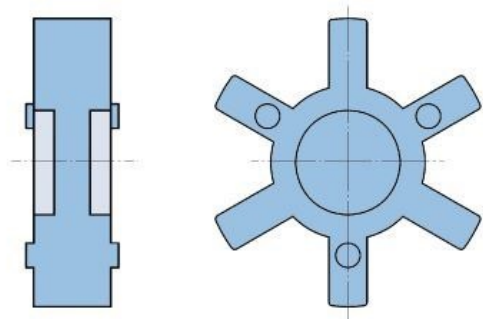

Size	70
Nominal torque (Nm)	5.77
Nominal torque (lbft)	4.26
Speed Max. (r/min)	14000
Weight	8
Weight (lbs)	17.64
Temperature range (°C)	-40 to 100
Angular misalignment (°)	1
Parallel misalignment (mm)	0.38
Parallel misalignment (in)	0.01