



Monitor mount PRO for 1 screen, wall mount

Article number	508923	Sales unit quantity	1 Piece
Colour	Silver	Sales unit EAN	4005546998442
Packaging unit	1 piece	Packing weight (gross)	1074 G
Base EAN	4005546998442	Country of origin	DE

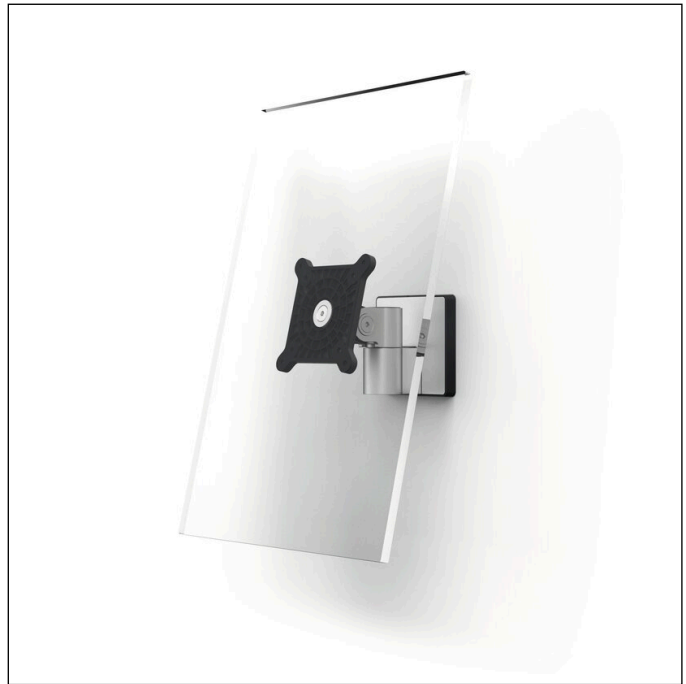

Logos and awards

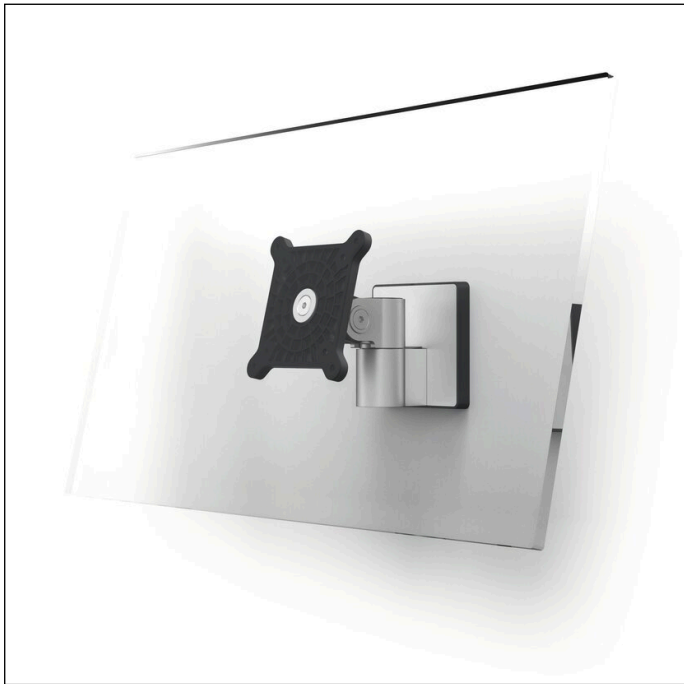

Product description

- Wall-mounted monitor mount for 1 screen
- Tilt and position of the monitor can be adjusted easily and individually to facilitate flexible working and presenting
- Can be rotated 360° for working in portrait or landscape mode
- Easy assembly with enclosed tools for secure wall mounting
- Universal VESA mount (75 x 75 mm or 100 x 100 mm)
- For standard or curved monitors from 21" to 27" [53.34 cm to 68.58 cm] weighing 3 to 8 kg
- 10-year warranty
- Made in Germany
- High-quality materials for a long lifespan: Aluminium and premium plastic
- Environmentally friendly in accordance with ISO 14021

Monitor mount PRO for 1 screen, wall mount

Product features

Outer width (mm)	130
Outer height (mm)	120
Outer depth / length	140 mm
Filling quantity / Filling quantity for	1 Monitor(s)
Brand	DURABLE
Display Size Monitor	53.3 cm [21"] - 86.4 cm [34"]
Suitable for curved monitors	Yes
Display rotatable (°)	360
Adjustable display which can be locked in place	No
Monitor swivel range	200° horizontal
Monitor Infinitely variable inclination	+ 85° / - 25°
Height adjustment from to	No
Movement capability	Rotates, tilts, pivots
Cable Management	Yes
Max. load capacity	Each 3 - 8 kg
VESA standard	75 x 75 mm, 100 x 100 mm
Assembly	Easy to construct
Warranty	10 years
Country of Origin	Made in Germany
Base / mount type	Wall mount