


plug socket with cable KMEB-2-24-2,5-LED

Part number: 174844

FESTO

pre-assembled, for VUVB, MEBH, MOEBH valves and N2 solenoids.

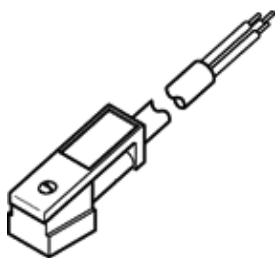

Data sheet

Feature	Value
Switching position indicator	LED
Mounting type	On solenoid valve with M2.5 central screw
Assembly position	Any
Product weight	200 g
Electrical connection	Plug socket angled Per DIN EN 175301-803 Plug pattern type C to EN 175301-803 4-pin
Nominal operating voltage DC	24 V
Protective earth connection	Available
Cable length	2.5 m
Cable diameter	6.2 mm
Cable structure	3x0,75
Protection class	IP65 to IEC 60529
Ambient temperature	-20 ... 80 °C
Materials note	Conforms to RoHS
Material cable sheath	TPE-U(PUR)
Material housing	PA POM
Material electrical contact	Bronze