

Ground wire choke, open design



Description

- Ground wire chokes (ground line chokes)
- THT-terminals

Standards

- EN 60938

Applications

- Separating the main earth line to periphery devices
- This type of chokes permits the building of a system free of ground wire loops

Weblinks

[pdf-datasheet](#), [html-datasheet](#), [General Product Information](#), [Approvals](#), [CE declaration of conformity](#), [RoHS](#), [CHINA-RoHS](#), [REACH](#), [e-Shop](#), [SCHURTER-Stock-Check](#), [Distributor-Stock-Check](#), [Detailed request for product](#)


Technical Data

Rated Current	16 - 25A @ Ta 40 °C
Rated inductance	2 - 4mH
Power Operating Frequency	< 5MHz
Terminal technic	THT
Material: Housing	UL 94V-0
Sealing Compound	UL 94V-0


Isolation Voltage	2kV eff., winding to ambient
Climatic Category	25/100/21 acc. to IEC 60068-1
Allowable Operation Temp.	-25 °C to 100 °C

Dimension


DENO-23-0001

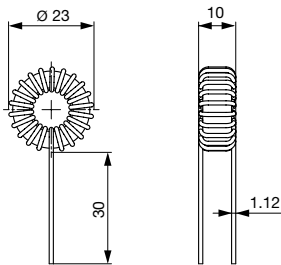

DENO-25-0001

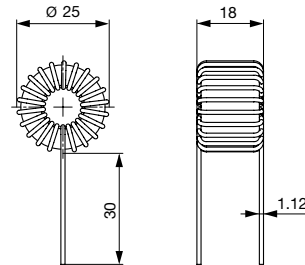

DENO-40-0001

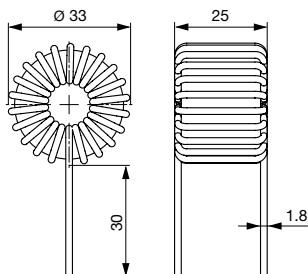

All Variants

I_n [A]	L_n [mH]	R_{cu} [mΩ]	f_{RES} [MHz]	Weight [g]	Packing unit [pcs.]	Order Number
16	2	15	0.3	13 g	100	DENO-23-0001
16	4	27	0.3	25 g	50	DENO-25-0001
25	4	10	0.3	20 g	50	DENO-40-0001

■ Most Popular.

Availability for all products can be searched real-time: <http://www.schurter.com/en/Stock-Check/Stock-Check-SCHURTER>