


Item no.: 289-457
 Product description: INTERFACE MODULE WITH SUB MINIATURE D-FEMALE CONNECTOR 25 POLE FOR MATING CONNECTORS WITH SOLDER CONNECTION MATING DIRECTION VERTICAL

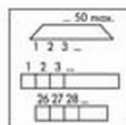

Produkt kann von Bild abweichen / product may differ

Packing unit 1 piece

RoHS compliant

Product group	6 (Electronics)
Operating voltage	AC / DC 125 V
Nominal current	1 A
Connector contact	plating. 0.5-0.8µm Au over 2µm Ni
Contact resistance	<= 10 mOhm
Performance level	2 / 200 mating cycles
Nominal voltage acc. to VDE 0110/1.89	50 V / 0,8 kV / 2
Cross section [mm²]	0.08 - 2.5 mm²
Cross section [AWG]	28 - 12 AWG
Connection method	CAGE CLAMP® CONNECTION
Weight	55.1 g
Height	19 mm
Height	0.748 in
Width	79 mm
Width	3.11 in
Depth	63.5 mm
Depth	2.5 in
Strip length from	5 mm

Strip length to	6 mm
Strip length	0.22 in
Mounting	TS 35

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected