


CF 500/DIE TC HC 10 - Crimp insert



1324137

<https://www.phoenixcontact.com/in/products/1324137>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

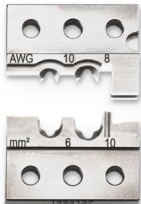

Die for CF 500 automatic crimping device, CK 4.0-ED... turned contacts, 2 marked die stations

Product description

For CK 4,0-ED... contacts

Your advantages

- Marked die stations for precise processing of corresponding cross sections

Commercial data

Item number	1324137
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	*****
Product key	BH323Z
GTIN	4063151614010
Weight per piece (including packing)	67.4 g
Weight per piece (excluding packing)	22.22 g
Customs tariff number	84799070
Country of origin	DE

CF 500/DIE TC HC 10 - Crimp insert



1324137

<https://www.phoenixcontact.com/in/products/1324137>

Technical data

Notes

Note on application	For 6.0 mm ² ... 10.0 mm ² turned crimp contacts from the CK4.0 ED... series, the packing slip includes a detailed list of the crimp contacts
---------------------	---

Product properties

Product type	Die
Compression	Square crimp

Crimping position 1

Max. cross section	6 mm ²
AWG max	10

Crimping position 2

Max. cross section	10 mm ²
AWG max	8

Connection data

Conductor connection

Cross section range, metric	6 mm ² ... 10 mm ²
Cross section range AWG	10 ... 8

Dimensions

Width	9 mm
Height	36 mm
Length	32 mm
Min. material thickness	6.05 mm
Max. material thickness	9 mm

Material specifications

Color	Nickel color
Material	Steel
Coating	nickel-plated

CF 500/DIE TC HC 10 - Crimp insert

1324137

<https://www.phoenixcontact.com/in/products/1324137>



Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/in/products/1324137>



EAC

Approval ID: RU C-DE.AI30.B.01549

CF 500/DIE TC HC 10 - Crimp insert



1324137

<https://www.phoenixcontact.com/in/products/1324137>

Classifications

ECLASS

ECLASS-11.0	17130192
ECLASS-12.0	17130192
ECLASS-13.0	17130192

ETIM

ETIM 9.0	EC002778
----------	----------

UNSPSC

UNSPSC 21.0	27111500
-------------	----------

CF 500/DIE TC HC 10 - Crimp insert



1324137

<https://www.phoenixcontact.com/in/products/1324137>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Not applicable, No electrical and electronic equipment (EEE), cannot be used in EEE
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

CF 500/DIE TC HC 10 - Crimp insert



1324137

<https://www.phoenixcontact.com/in/products/1324137>

Mandatory accessories

CF 500/COV - Covering hood

1212250

<https://www.phoenixcontact.com/in/products/1212250>



Protective hood for CF 500 automatic crimping device, for ferrules: 10 mm² ... 25 mm² (AI 25, AI 50), TWIN ferrules: 6 mm² ... 16 mm² (AI-TWIN 16), uninsulated cable lugs: 16 mm² (RC 16), turned contacts: 6 mm² ... 10 mm² (TC HC 10)

Accessories

CK4,0-ED-10,00M AG - Crimp contact

1274091

<https://www.phoenixcontact.com/in/products/1274091>



Crimp contact, contact diameter: 4 mm, turned, Pin, contact material: Copper alloy, lead-free, contact surface: silver-plated, connection cross section: 10 mm² ... 10 mm², AWG 8

CF 500/DIE TC HC 10 - Crimp insert

1324137

<https://www.phoenixcontact.com/in/products/1324137>



CK4,0-ED-10,00F AG - Crimp contact

1274085

<https://www.phoenixcontact.com/in/products/1274085>



Crimp contact, contact diameter: 4 mm, turned, Socket, contact material: Copper alloy, lead-free, contact surface: silver-plated, connection cross section: 10 mm² ... 10 mm², AWG 8

CK4,0-ED-6,00M AG - Crimp contact

1274092

<https://www.phoenixcontact.com/in/products/1274092>



Crimp contact, contact diameter: 4 mm, turned, Pin, contact material: Copper alloy, lead-free, contact surface: silver-plated, connection cross section: 6 mm² .. . 6 mm², AWG 10

CF 500/DIE TC HC 10 - Crimp insert

1324137

<https://www.phoenixcontact.com/in/products/1324137>



CK4,0-ED-6,00F AG - Crimp contact

1274086

<https://www.phoenixcontact.com/in/products/1274086>



Crimp contact, contact diameter: 4 mm, turned, Socket, contact material: Copper alloy, lead-free, contact surface: silver-plated, connection cross section: 6 mm² .. 6 mm², AWG 10

UNIFOX RT-CK 4.0 - Contact removal tool

1072064

<https://www.phoenixcontact.com/in/products/1072064>



Contact removal tool, for rotated CK-4,0-... contacts

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.
A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420
info@phoenixcontact.co.in