

Flexible Printed Circuit Connectors — FPC

Virtual Sample Kit

With one click on the part number you can:

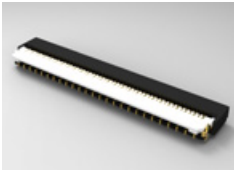
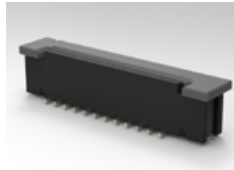
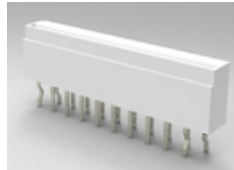
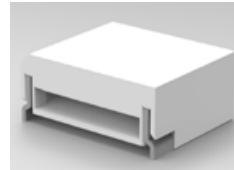
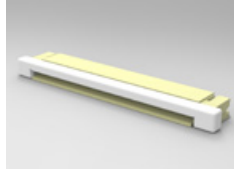
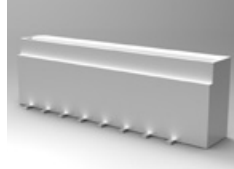
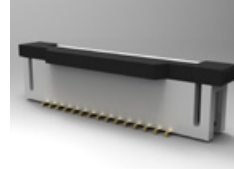
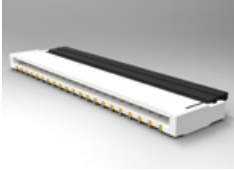
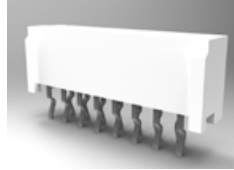
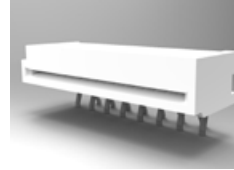
- View Product Details
- View product drawing or related specifications
- View 3D pdf
- Request sample

Note: Kit box p/n 1-1773705-8

www.te.com/products/consumervirtualsamplekits



Flexible Printed Circuit Connectors — FPC

0.25mm-41P-BF-L  1-2040832-6	0.3mm-51P-FF-L  5-2041390-1	0.5mm-24P-P-VT  2-1734742-4	1mm-20P-nonZIF-VT Through Hole  2-84984-0	1mm - 4P-nonZIF-U Surface Mount  84981-4
	0.3mm-39P-BF-L Narrow Type  1-2013496-5	0.5mm - 40P-P-L  4-1734592-0	1mm - 23P-nonZIF-VT Surface Mount  2-84982-3	1mm-16P-P - VT  1-1734248-6
	0.3mm-39P - BF-U Narrow Type  1-2013928		1.25mm-30P-nonZIF-VT Through Hole  3-84534-0	1.25mm-4P-nonZIF-U Through Hole  84533-4

LEGEND: **BF**=Back Flip Lock **FF**=Front Flip Lock **L**=Lower Contact **U**=Upper Contact **P**=Plunger Actuator **VT**=Vertical