




LED FIL WarmDim A60 E27 6W (60W) 806lm 927-922 Opal

Article number: 146727

BAI LED Filament WarmDim GLS A60 E27 6W (60W) 806lm Dimmable 927-922 Opal 230V-240V 320° 60x105mm D2W DTW Dim To Warm Dimtone Glowdim LED-lamp

With Bailey's WarmDim filament lamp you can go from cozy warm light (2200K) to functional warm white light (2700K) and back again in literally no time. The graceful dim-to-warm LED filaments also give this light source a similar appearance to that of the incandescent wires. Ideal, for example, in fixtures or pendant sets above (dining) tables or in floor lamps to create a living room atmosphere. Consult the dimmer list to choose the correct dimmer.

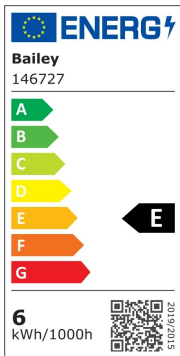

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED FIL WarmDim A60 E27 6W (60W) 806lm 927-922 Opal
Brand	Bailey
Productseries	LED Filament GLS
Producttype	A60 WarmDim Opal

ETIM specifications

Socket	E27
Luminous flux [lm]	806 - 806
Nominal voltage [V]	220 - 240
Lamp power [W]	6 - 6
Colour temperature [K]	2200 - 2700
Diameter [mm]	60
Length [mm]	105
Dimmable	Yes
Lamp shape	Pear-shape
Beam angle [°]	320 - 320
Colour	White
Type of glass/cover	Opal
Lamp designation	Other
Colour rendering index CRI	90-100
Voltage type	AC
Filament lamp	Yes
Rated luminous flux according to IEC 62612 [lm]	806
Power factor	0.7
Lamp efficacy [lm/W]	134
Nominal current [mA]	34 - 34
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	White
Average nominal lifetime [h]	25000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	10000
Weighted energy consumption in 1000 hours [kWh]	6
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG0
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	Yes
Dimming phase cut-on (leading edge)	Yes
Dimming Touch and Dim	No
Dimming Zigbee	No

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	E
With twilight switch	No
Material of light bulb	Glass

Complementary articles



140639
Table Lamp E27 Concrete



140640
Table Lamp Round E27 Wood