


Professionally approved products.

Clamps

Horizontal Steel Toggle Clamp 75Kg Holding Force

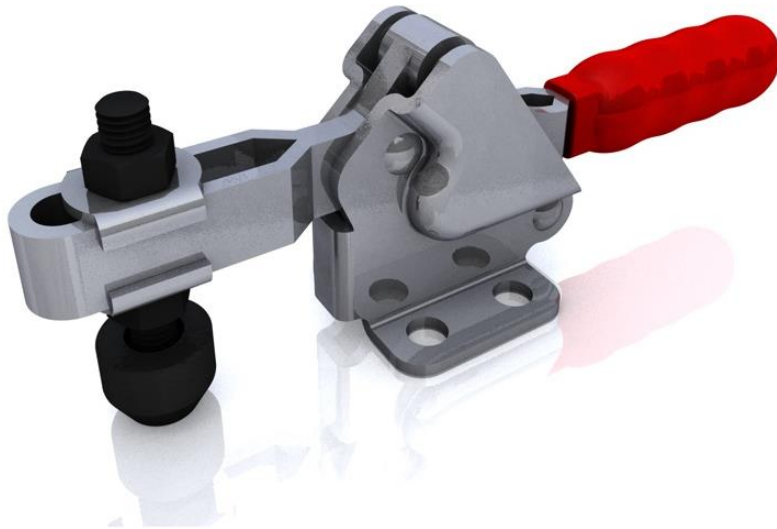

[RS Stock No. 254-620](#)

Specification:

- Zinc plated steel construction
- Vinyl grip for operator comfort
- Supplied with steel spindle and one neoprene cover complete with nuts & washers
- Solid rivets
- 2D & 3D drawings available for download
- Handle locks in horizontal position
- Spindle adjusts in both vertical & horizontal plain
- Side plates to prevent finger pinch
- Also available in stainless steel
- Optional Items
- Model 261404 Neoprene Tipped Spindle
- Model 254816 Swivel Foot Spindle
- Model 261432 Neoprene Caps for use with Swivel Foot Spindle

