




Connectors > PCB Connectors > Backplane Connectors > Backplane Connector Housings

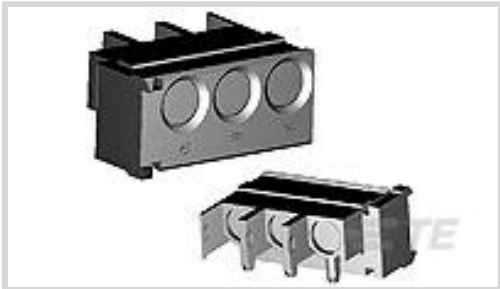

Number of Positions: 3

Number of Rows: 1

Connector & Housing Type: **Receptacle**

Connector & Contact Terminates To: **Printed Circuit Board**

Features

Product Type Features

Connector & Housing Type	Receptacle
Connector & Contact Terminates To	Printed Circuit Board

Configuration Features

Number of Positions	3
Number of Rows	1

Body Features

Primary Product Color	Gray
-----------------------	------

Contact Features

Contact Type	Socket
--------------	--------

Mechanical Attachment

Mating Retention	With
Mating Alignment Type	Multi-Purpose Center
Mating Alignment	With

Housing Features

Housing Material	Polyester - GF
Centerline (Pitch)	2 mm

Dimensions

Connector Height	11.4 mm
Connector Length	24.95 mm



Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

Packaging Features

Packaging Method	Tray
------------------	------

Product Compliance


For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Not Yet Reviewed
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulations, TE’s information on SVHC in articles for this part number is still based on the European Chemical Agency (ECHA) ‘Guidance on requirements for substances in articles’(Version: 2, April 2011), applying the 0.1% weight on weight concentration threshold at the finished product level. TE is aware of the European Court of Justice ruling of September 10th, 2015 also known as O5A (Once An Article Always An Article) stating that, in case of ‘complex object’, the threshold for a SVHC must be applied to both the product as a whole and simultaneously to each of the articles forming part of its composition. TE has evaluated this ruling based on the new ECHA “Guidance on requirements for substances in articles” (June 2017, version 4.0) and will be updating its statements accordingly.

Also in the Series | Z-PACK 2mm HM

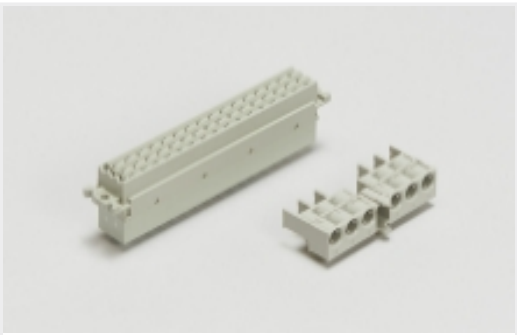


Backplane Connector Housings(4)

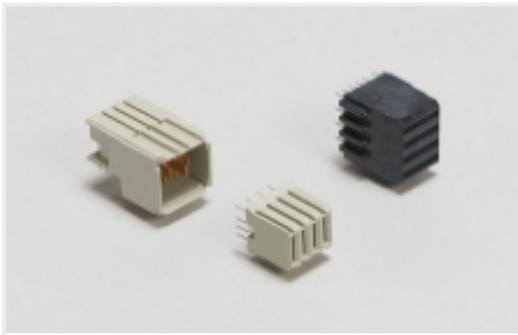

Backplane Power Connectors(1)




Connector Caps & Covers(62)

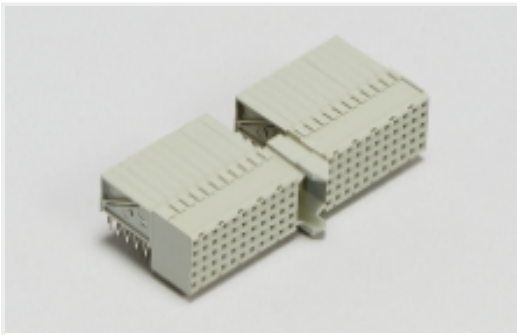

Hard Metric Backplane Connectors (266)



Insertion & Extraction Tools(2)

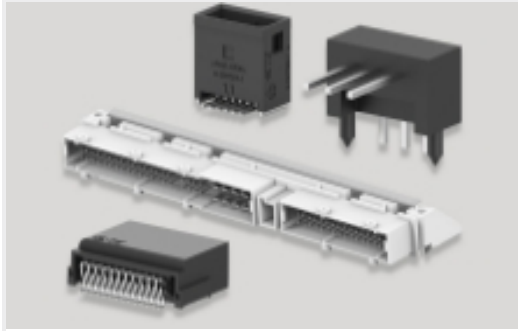

PCB Headers & Receptacles(46)




Rectangular Power Connectors(46)


Customers Also Bought



TE Part #1-66108-5
III+ SKT,26-24,TIN,STRIP

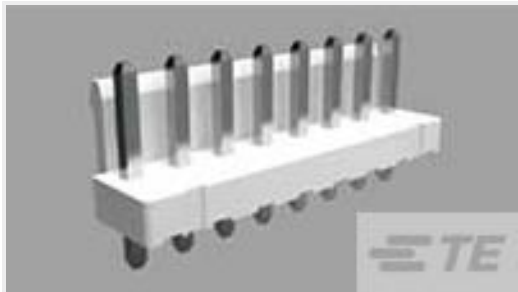


TE Part #1-1744037-0
10P EC PWR.200 CL HDR ASSY VRT

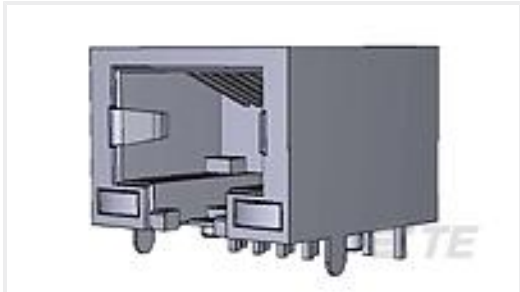


TE Part #1734324-3
RJ45,8P8C,w/ Y,G LED,shieled,dip, 30u" Au



TE Part #2308107-1
DDR4 DIMM 288 PIN TH TYPE

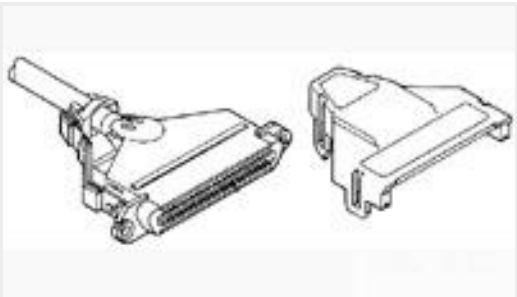

TE Part #554946-2
COVER KIT, 180 DEG,50 POS,SHLD

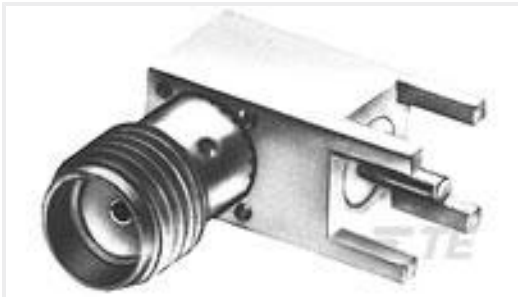

TE Part #1053396-1
2064 8001 90




TE Part #221117-4
KIT, COMMERIAL SMA PLUG ASSY



TE Part #554954-1
PLUG KIT,50 POSN, SCR LK, SHLD



TE Part #1734595-8
1.0 WTB SR VT HDR 8 POS

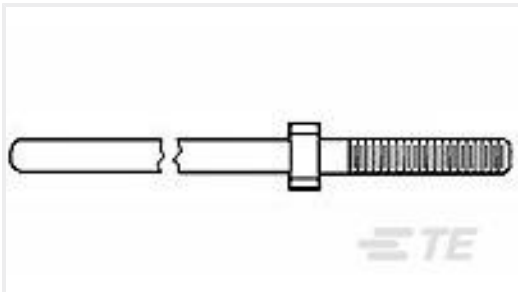

TE Part #532828-5
HDI STATIC CHRGE GDE PIN PLTD

Document



CAD Files

Customer View Model

ENG_CVM_CVM_100752-1_O.2d_dxf.zip

English

3D PDF

3D

Customer View Model

ENG_CVM_CVM_100752-1_O.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_100752-1_O.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

1.5D/2.5D TYPE C COAX CONNECTOR

English

Product Specification

English