


1726207-2RS1

Popular item

Dimensions

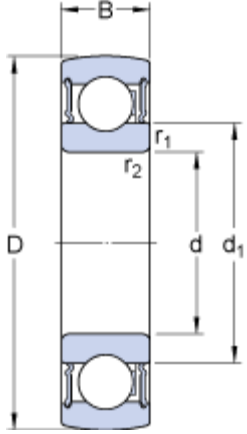

d	35	mm
D	72	mm
B	17	mm
d ₁	≈ 46.94	mm
r _{1,2}	min. 1.1	mm

Calculation data

Basic dynamic load rating	C	25.5	kN
Basic static load rating	C ₀	15.3	kN
Fatigue load limit	P _u	0.655	kN
Limiting speed ¹⁾		6300	r/min
Calculation factor	f ₀	14	

Mass

Mass complete bearing		0.28	kg
-----------------------	--	------	----

Associated products

Rubber seating ring		RIS 207 A	
---------------------	--	-----------	--