


DIN Distribution Box for up to 12FO

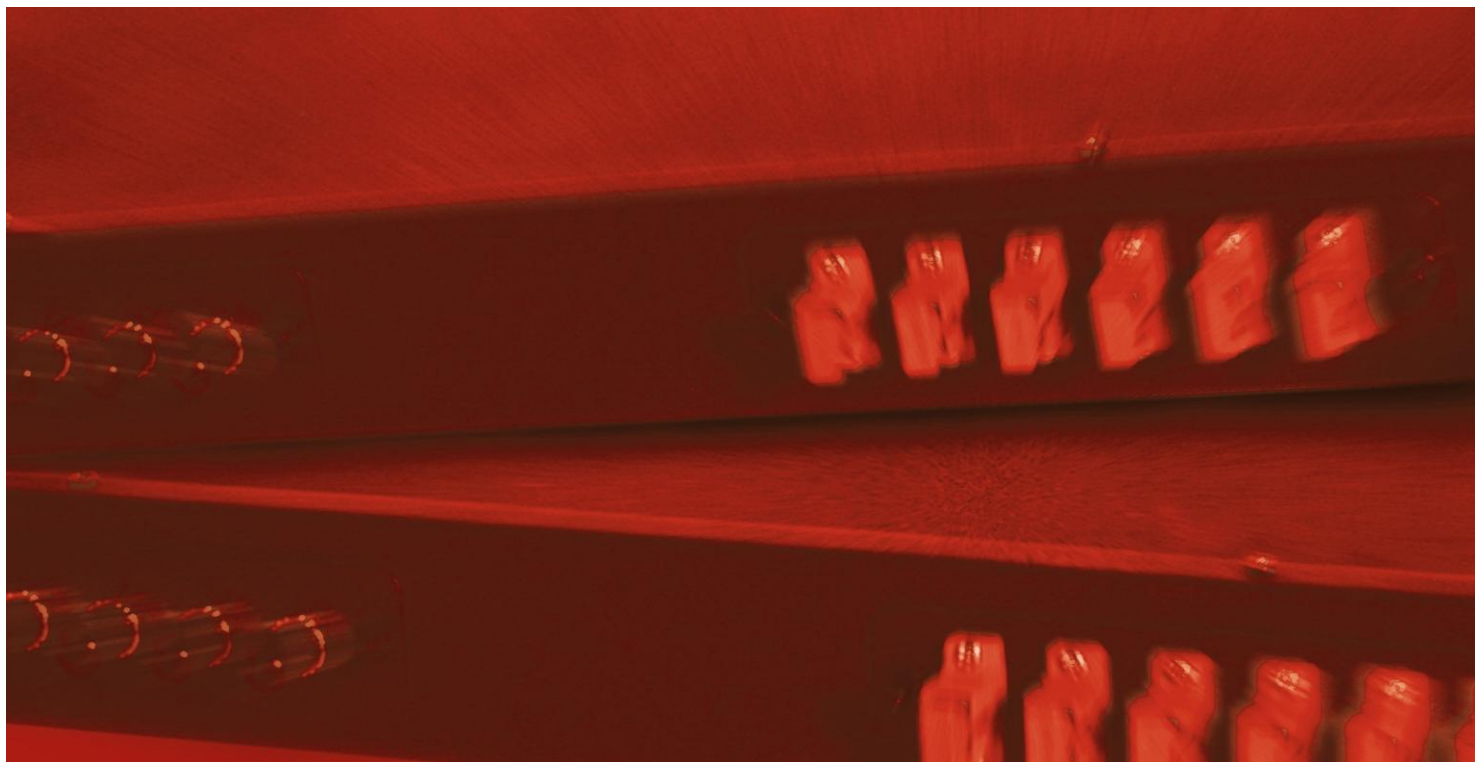

TECHNICAL SPECIFICATION



GENERAL

The DIN distribution box can hold up to 12FO and is suitable for indoor applications.

The box is supplied with a mounting bracket for DIN rails, and can hold a multifibre cable with a maximum diameter of 10 mm.

The patchcords can be connected to the box through a front panel equipped with adapters.

PRODUCT DESCRIPTION



Metal box supplied with:

- Cover with 4 fixing screws
- Rear mounting bracket for DIN rail
- 4 cable entry points equipped with:
 - 2 cable glands suitable for cables with a maximum diameter of 10 mm
 - 2 blanking plugs
- 2 screw clamps to hold the cable strength member in place
- Removable splice cassette that can hold up to 12 splice protection sleeves
- Front panel with:
 - Type 1 – 8 holes for SC simplex, E2000 simplex, LC duplex, ST simplex or FC simplex adapters
 - Type 2 – 6 holes for ST duplex, SC duplex or LC quad adapters (the latter only with pre-connectorised cables)

CHARACTERISTICS

- | | |
|---------------|---------------------|
| • Material | Painted steel |
| • Colour | RAL 7035 Light Grey |
| • Application | Indoor |
| • Mounting | On DIN rail |
| • Size [mm] | 126 x 130 x 35 |
| • Weight | 590 g |

TECHNICAL DRAWING

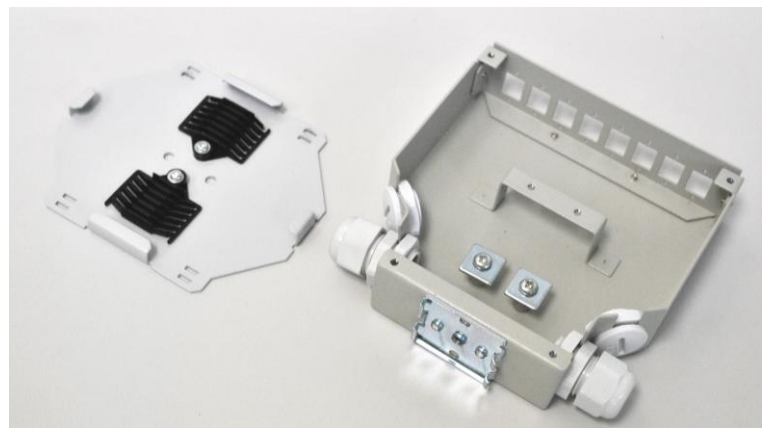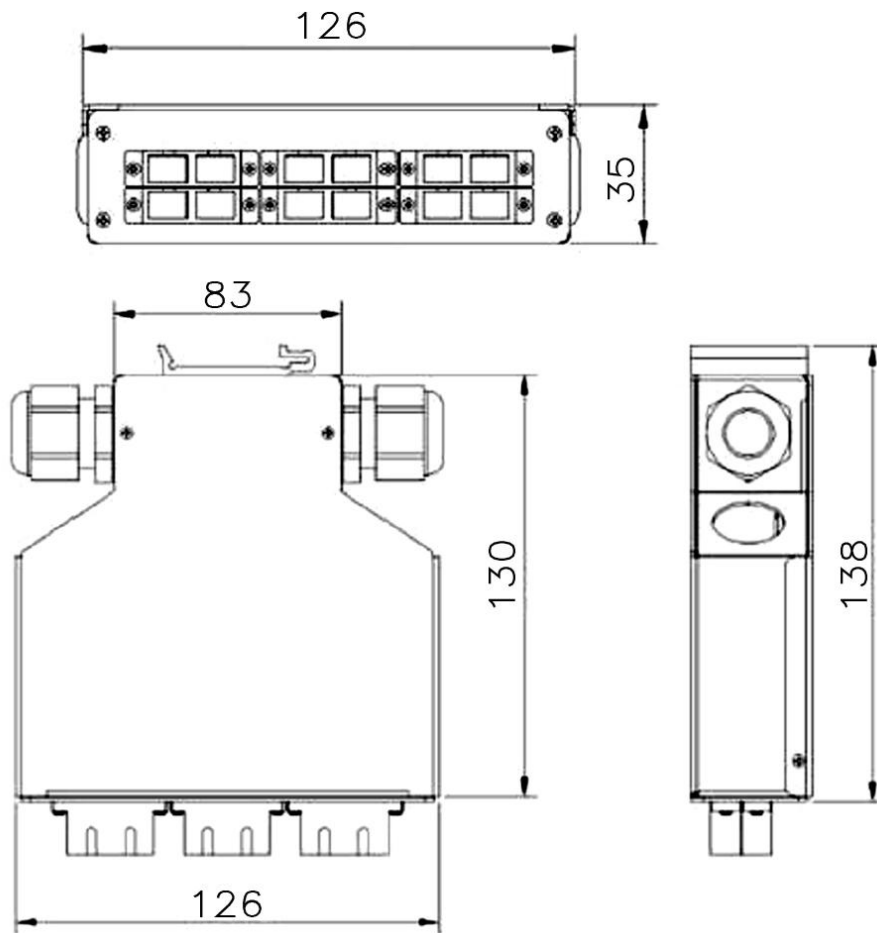

E N D O F S P E C I F I C A T I O N