

Products Categories

- Part No. index
- Cutters & Pliers
- Wire strippers
- Crimpers
- Tweezers
- Screwdrivers & Wrenches
- Metal working
- Parts cases
- Tool cases
- Tool kits
- Soldering irons & Solder
- Parts & Solder removal equipment
- Measuring instruments
- Optical equipment
- Antistatic products
- Clean products
- Maintenance & Safety products


Antistatic products > Rubber mats

F-707 / 708 / 710 ESD PVC MAT (Green)



Part No.	External dimensions m	Thickness mm	ESD standard Ω	Weight kg
F-707	1 (W) × 1 (L)	1.5	Point to point resistance Rp 1×10 ⁸	2.2
F-708	1 (W) × 1.8 (L)			4.0
F-710	1 (W) × 10 (L)			22.2

■ The ground cord is not provided as an accessory. It can be ordered separately.

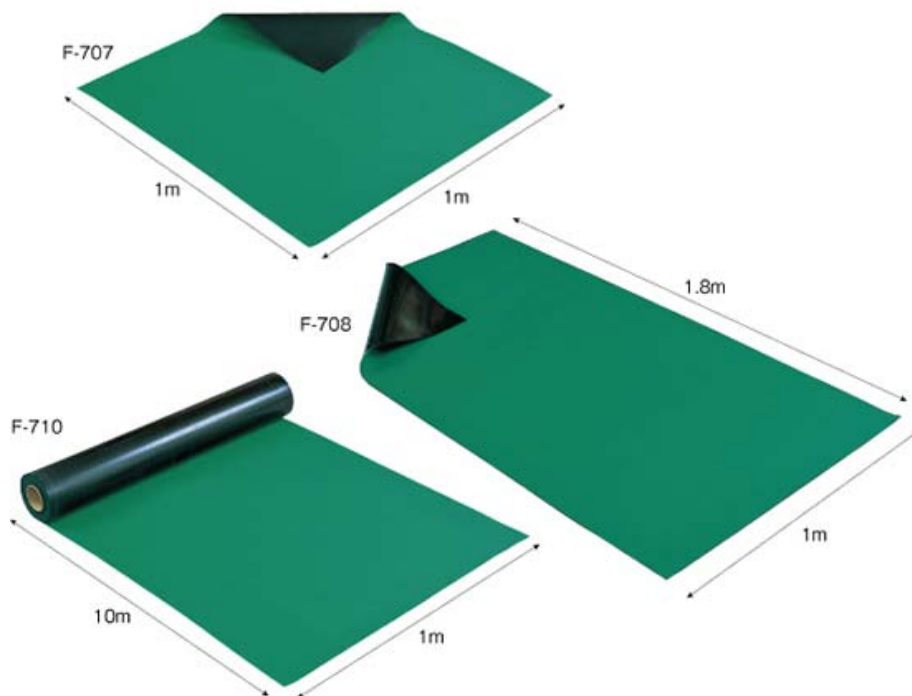

Related products

F-127 GROUND CORD



- Wire dia. × length: 1.25 mm² × 2 m
- Quantity: 2-piece pack



F-127-1 TERMINAL SET



- Wire dia. × length: 1.25 mm² × 2 m
- Quantity: 2-piece pack



F-27 GROUND CORD




- Wire dia. × length: 1.25 mm² × 2 m
- For conductive (ESD) rubber mat
- Quantity: 2-piece pack

F-29-1 STUD

- Application: For use with conductive rubber mats
- Quantity: 5-piece pack



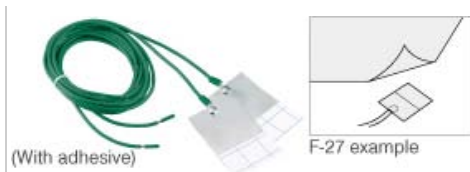

F-28 GROUND PLATE

- For conductive rubber mat
- Quantity: 10-piece pack



F-29-2 PUNCH KIT

- Quantity: 1 set (punch & chisel)



Example of pre-cut hole & clinching stud

F-24 GROUND CORD

- With 1 MΩ resistor

