


Deep groove ball bearings, single row, shield on both sides



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
17	35	10	6,37	3,25	0,137	45000	22000	0,039	6003-2Z *

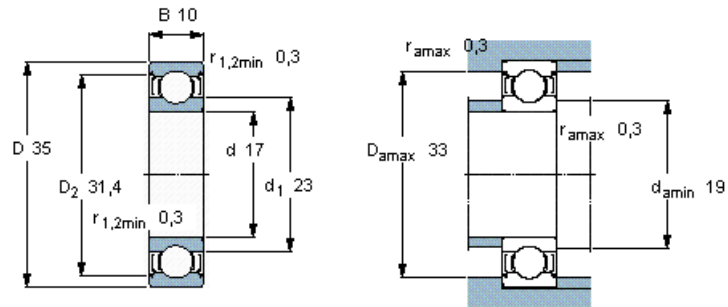

Calculation factors

k_r 0,025
 f_0 14