


Product data sheet

Characteristics

DF2FA100

NFC cartridge fuses, Tesys GS, cylindrical, 22 mm x 58 mm, fuse type aM, 500 VAC, 100 A, without striker

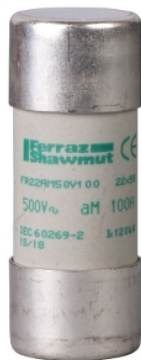

Main

Range of product	TeSys fuse-disconnector
Product or component type	Cartridge fuse
Device short name	DF2
[Ue] rated operational voltage	500 V AC
Fuse size	22 x 58 mm
Fuse type	NFC
Quantity per set	Set of 10

Complementary

[In] rated current	100 A 500 V
Fuse curve	AM
Net weight	0.045 kg

Packing Units

Package 1 Weight	49 g
Package 2 Weight	526 g
Package 3 Weight	6.499 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins

Contractual warranty

Warranty	18 months
----------	-----------

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.