


FAST SANDING OF PAINT AND WOOD

EXPERT C470 Sandpaper

EXPERT

- ① Exceptional abrasion with Bosch Surface Structure
- ② Grain alignment during production ensures aggressive cut
- ③ Grain distribution optimised for high-speed sanding

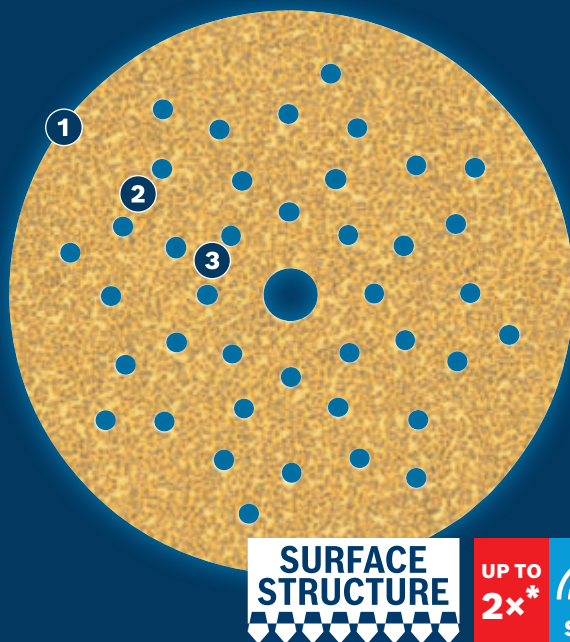


* vs. Bosch C420



BOSCH

EXPERT C470 SANDING DISCS

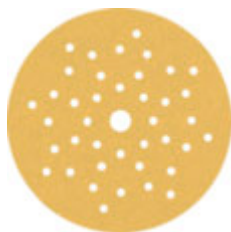

- ▶ Ideal for highly effective fast sanding of flat surfaces; to remove old paint; or to smooth, prepare and finish surfaces
- ▶ EXPERT Abrasives - the very best for all trades
- ▶ Up to 2x faster than Bosch C420 Sandpaper
- ▶ Just stick it on with hook and loop

PRODUCT PROPERTIES				ORDERING INFORMATION				
Disc diameter mm	Grit	Perforation	Packaging type	Pack quantity	Minimum order quantity	Barcode 4 059 952...	Part number	
125	40	Multi hole system	C1a	5	5	544 304	2 608 901 092	
125	60	Multi hole system	C1a	5	5	544 311	2 608 901 093	
125	80	Multi hole system	C1a	5	5	544 328	2 608 901 094	
125	100	Multi hole system	C1a	5	5	544 335	2 608 901 095	
125	120	Multi hole system	C1a	5	5	544 342	2 608 901 096	
125	180	Multi hole system	C1a	5	5	544 359	2 608 901 097	
125	240	Multi hole system	C1a	5	5	544 366	2 608 901 098	
125	320	Multi hole system	C1a	5	5	544 373	2 608 901 099	
125	400	Multi hole system	C1a	5	5	544 380	2 608 901 100	
150	40	Multi hole system	C1a	5	5	544 403	2 608 901 102	
150	60	Multi hole system	C1a	5	5	544 410	2 608 901 103	
150	80	Multi hole system	C1a	5	5	544 427	2 608 901 104	
150	100	Multi hole system	C1a	5	5	544 434	2 608 901 105	
150	120	Multi hole system	C1a	5	5	544 441	2 608 901 106	
150	180	Multi hole system	C1a	5	5	544 458	2 608 901 107	
150	240	Multi hole system	C1a	5	5	544 465	2 608 901 108	
150	320	Multi hole system	C1a	5	5	544 472	2 608 901 109	
150	400	Multi hole system	C1a	5	5	544 489	2 608 901 110	
125	40	Multi hole system	C0a	50	1	544 625	2 608 901 124	
125	60	Multi hole system	C0a	50	1	544 632	2 608 901 125	
125	80	Multi hole system	C0a	50	1	544 649	2 608 901 126	
125	100	Multi hole system	C0a	50	1	544 656	2 608 901 127	
125	120	Multi hole system	C0a	50	1	544 663	2 608 901 128	
125	150	Multi hole system	C0a	50	1	544 670	2 608 901 129	
125	180	Multi hole system	C0a	50	1	544 687	2 608 901 130	
125	220	Multi hole system	C0a	50	1	544 694	2 608 901 131	
125	240	Multi hole system	C0a	50	1	544 700	2 608 901 132	
125	320	Multi hole system	C0a	50	1	544 717	2 608 901 133	
125	400	Multi hole system	C0a	50	1	544 724	2 608 901 134	
150	40	Multi hole system	C0a	50	1	544 731	2 608 901 135	
150	60	Multi hole system	C0a	50	1	544 748	2 608 901 136	
150	80	Multi hole system	C0a	50	1	544 755	2 608 901 137	
150	100	Multi hole system	C0a	50	1	544 762	2 608 901 138	
150	120	Multi hole system	C0a	50	1	544 779	2 608 901 139	
150	150	Multi hole system	C0a	50	1	544 786	2 608 901 140	
150	180	Multi hole system	C0a	50	1	544 793	2 608 901 141	
150	220	Multi hole system	C0a	50	1	544 809	2 608 901 142	
150	240	Multi hole system	C0a	50	1	544 816	2 608 901 143	
150	320	Multi hole system	C0a	50	1	544 823	2 608 901 144	



BOSCH

EXPERT C470 SANDING DISCS

PRODUCT PROPERTIES				ORDERING INFORMATION				
Disc diameter mm	Grit	Perforation	Packaging type	Pack quantity	Minimum order quantity	Barcode 4 059 952...	Part number	
150	400	Multi hole system	C0a	50	1	544 830	2 608 901 145	



BOSCH