



CorePro LEDspot MV

Corepro LEDspot 4.6-50W GU10 830 36D

CorePro LEDspots are a perfect fit for spot lighting and deliver warm halogen-like light. They are compatible with most existing fixtures with a GU10 or E27 base and are designed as a retrofit replacement for halogen or incandescent spots. CorePro LEDspots deliver significant energy savings and minimize maintenance cost.

Product data

General Information	
Cap-Base	GU10 [GU10]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	15000 h
Switching Cycle	50000X
Technical Type	4.6-50W
Light Technical	
Color Code	830 [CCT of 3000K]
Beam Angle (Nom)	36 °
Luminous Flux (Nom)	370 lm
Luminous Intensity (Nom)	740 cd
Color Designation	White (WH)
Correlated Color Temperature (Nom)	3000 K
Luminous Efficacy (rated) (Nom)	80.00 lm/W
Color Consistency	<6
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Luminous Flux in 90° Cone (Rated)	370 lm
Operating and Electrical	
Input Frequency	50 to 60 Hz
Power (Nom)	4.6 W


Lamp Current (Nom)	39 mA
Wattage Equivalent	50 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.5
Voltage (Nom)	220-240 V
Temperature	
T-Case Maximum (Nom)	72 °C
Controls and Dimming	
Dimmable	No
Approval and Application	
Energy Efficiency Label (EEL)	A+
Suitable For Accent Lighting	Yes
Energy Consumption kWh/1000 h	5 kWh
Product Data	
Full product code	871869672837600
Order product name	Corepro LEDspot 4.6-50W GU10 830 36D
EAN/UPC - Product	8718696728376
Order code	929001218102

CorePro LEDspot MV

Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929001218102

Net Weight (Piece)	0.038 kg
--------------------	----------


Dimensional drawing

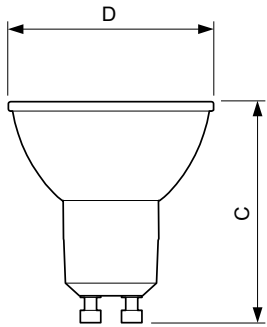

GU10 230V 4W-35W 260lm 100D 2700K GU10ND

Product	D	C
Corepro LEDspot 4.6-50W GU10 830 36D	50 mm	54 mm

 
Photometric data



Standard Reference 01 | Photo Lighting 01 | Page 17

LEDspot,PAR38 11W 900lm 3000K



CorePro LEDspotMV 50W GU10 830 36D CLA

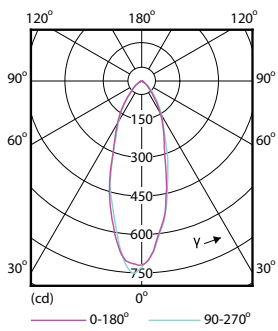

CorePro LEDspotMV 50W GU10 830 36D CLA

CorePro LEDspot MV

Lifetime

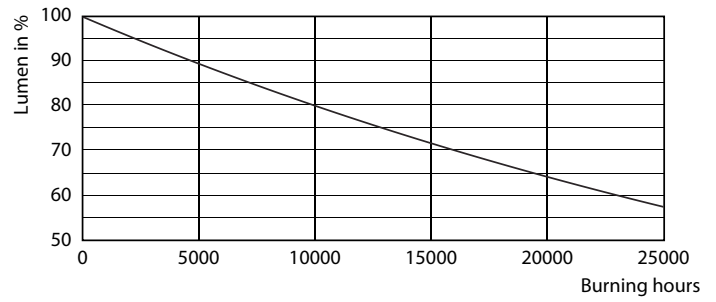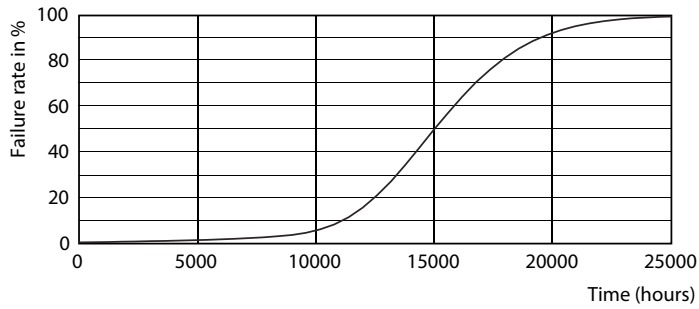

CLA LEDspotMV 50W GU10 827 36D ND

CLA LEDspotMV 50W GU10 827 36D ND

